


**Rittal – The System.**

Faster – better – everywhere.

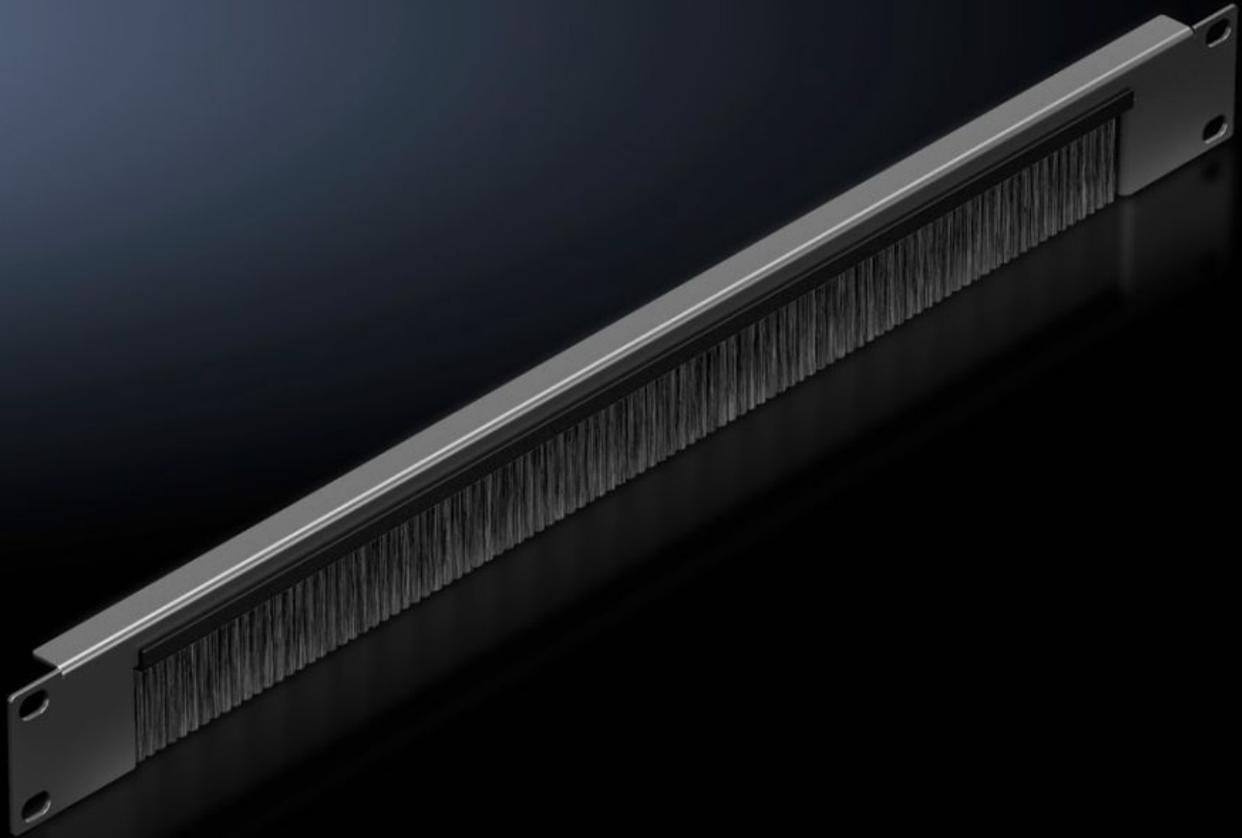

**DK 5302.202**

**Cable management panel with  
brush strip**

State: 05/04/2026 (Source: [rittal.com/ro-ro](http://rittal.com/ro-ro))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 5302.202 - Cable management panel with brush strip 482.6 mm (19")

With cut-out 390 x 40 mm (2 U) or 390 x 20 mm (1 U) with brush insert, accommodation facility for cable clamp straps.



## Features

Model No.	DK 5302.202
Product description	For convenient, simple cable routing between two areas separated by a 482.6 mm (19") mounting level, for example, between the front and rear areas of the 482.6 mm (19") mounting level.
Benefits	To make the cable entry larger, two panels are easily combined with one another
Applications	For locking and simultaneous cable routing in installation zones to the 1 U, 482.6 mm (19") mounting standard
Material	Sheet steel Brush strip: Plastic, UL 94 HB, halogen-free Brush strip fibres: Plastic PA6, halogen-free Brush strip mounting body: Plastic PVC, contains halogen
Surface finish	Spray-finished
Colour	RAL 9005
Mounting cut-out	Width:390 mm Height:30 mm
Dimensions	Width: 482.6 mm
Units	1 U

# Features

Packs of	1 pc(s).
Net weight	0,2 kg
Gross weight	0,243 kg
PCF per pack (cradle-to-gate)	0.9 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	73269098
ETIM 9	EC000322
ECLASS 8.0	27400604
Product description	Cable gland panel with brush strip, 1 U, 482.6 mm (19"), sheet steel, RAL 9005