


# Rittal – The System.

Faster – better – everywhere.

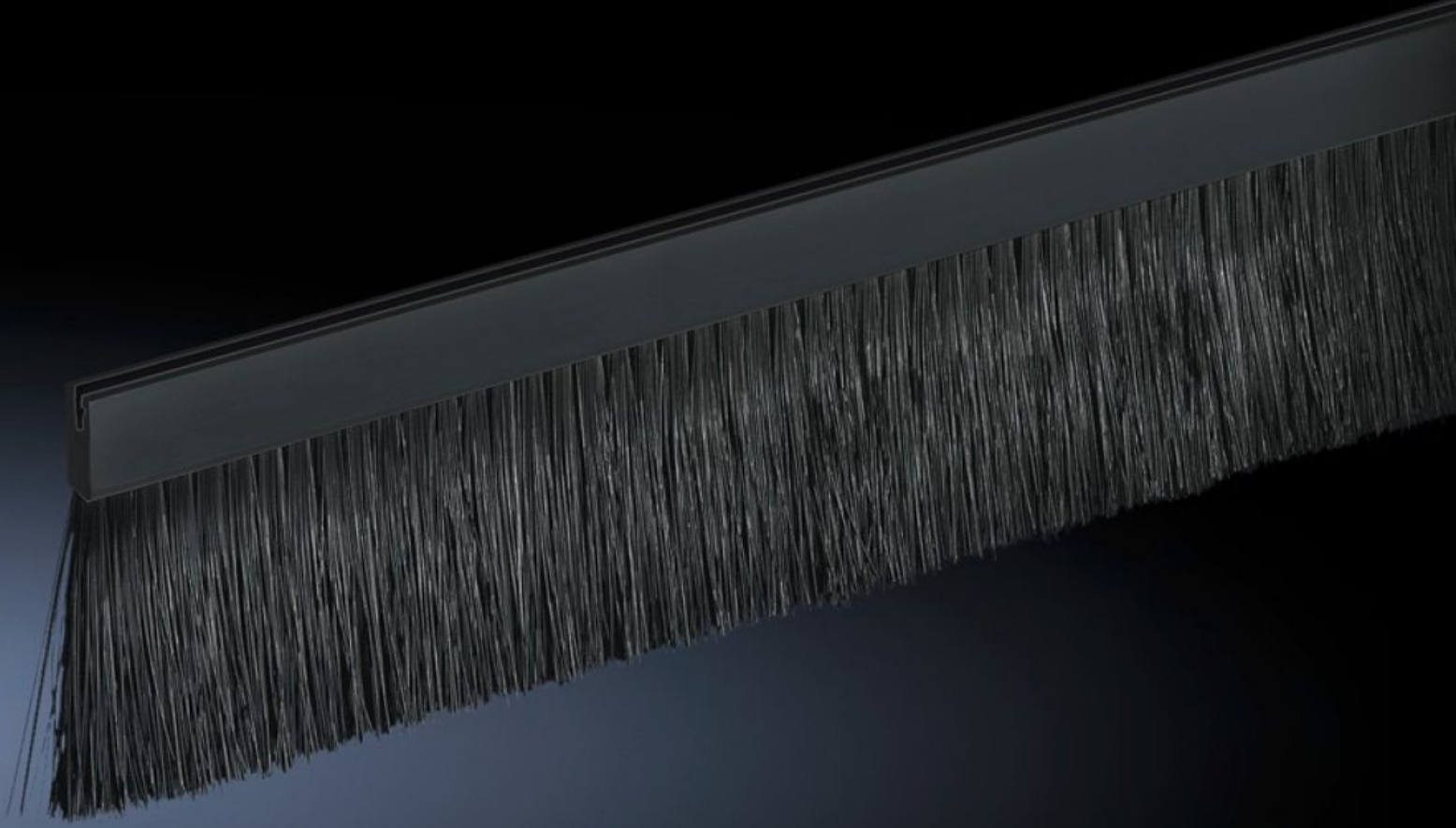

## DK 7072.200

## Brush strip

State: 07/07/2026 (Source: [rittal.com/ro-ro](http://rittal.com/ro-ro))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7072.200 - Brush strip

Cut-outs for cable routing at any given positions in the side panel, rear panel, doors, roof and gland plate may be finished off attractively by simply attaching the brush strip.

## Features

|                          |   |
|--------------------------|---|
| Model No.                | DK 7072.200   |
| Product description      | For individual installation of enclosure panels, gland plates and panels. Cut-outs for cable routing at any given positions in the side panel, rear panel, doors, roof and base plate may be finished off attractively by simply attaching the brush strip. |
| Benefits                 | Snap-on surface: 10 mm  |
| Function principle       | Maximum cut-out height: 38 mm   |
| Material                 | Plastic sheathing: 18 mm<br>Brush strip: Plastic, UL 94-HB  |
| Bristle length           | 30 mm   |
| Length                   | 2 m   |
| Dimensions               | Length: 2 m   |
| For material thicknesses | 0.6 - 1.5 mm  |
| Packs of                 | 1 pc(s).  |
| Net weight               | 0,43 kg   |
| Gross weight             | 0,433 kg  |
| Customs tariff number    | 96035000  |
| ETIM 9                   | EC012298  |
| ECLASS 8.0               | 27142421  |
| Product description      | DK Brush strip, L: 2 m, bristle length: 30 mm, for metal thickness: 0.6-1.5 mm  |

## Tender text

Brush strip

Brush strip, L: 2000 mm,  
for sheet thickness: 0.6-1.5 mm

Bristle length: 30 mm

Plastic jacket: 18 mm

Attachable area: 10 mm

Maximum cut-out height: 38 mm