
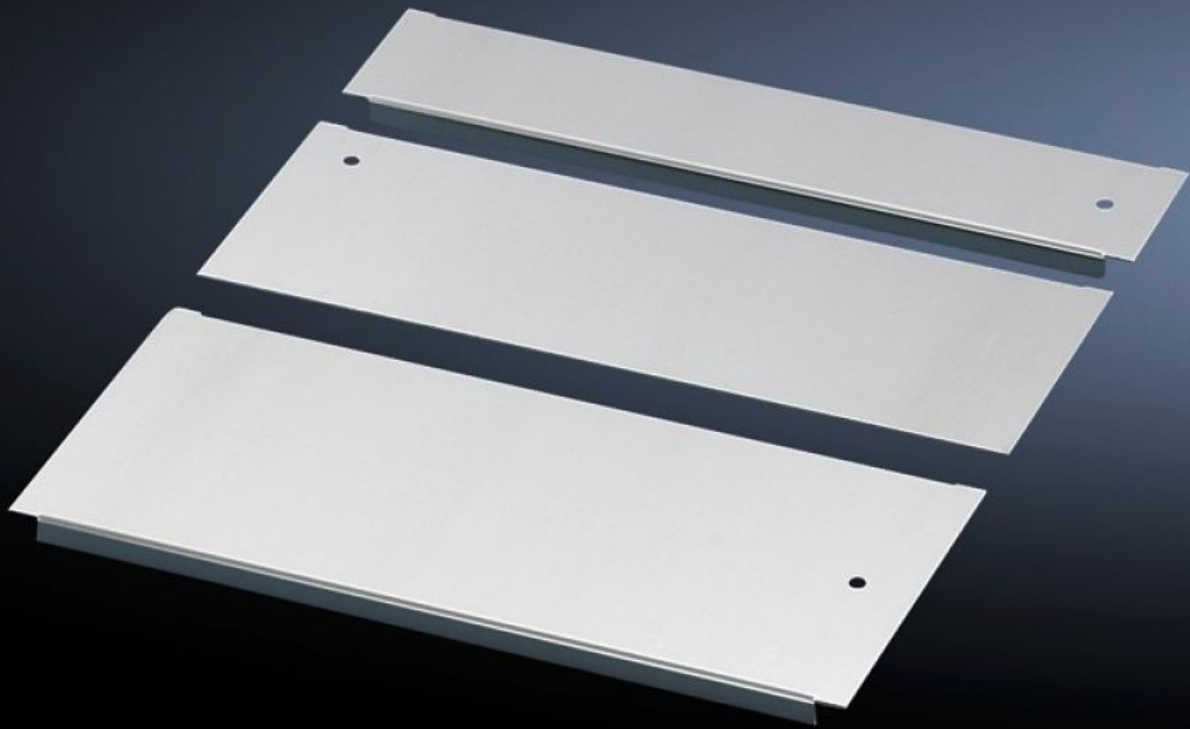


**Rittal – The System.**

Faster – better – everywhere.

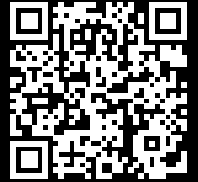

# TS 7825.384

## Gland plate, multi-piece

State: 05/04/2026 (Source: [rittal.com/ro-ro](http://rittal.com/ro-ro))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TS 7825.384 - Gland plate, multi-piece for DK-TS

Gland plate, multi-piece for DK-TS, in accordance with the enclosure depth any combination is possible.

## Features

Model No.	TS 7825.384
Product description	Any combination possible.
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Pack of 1 set of gland plates including sliding plate for cable entry, sealing tape and assembly parts.
Note	For the size variant 800 x 800 mm, the gland plate included with the supply of pre-configured network racks should be additionally used.
To fit	Enclosure type: TS 8 Width: 800 mm Depth: 1,000 mm
Packs of	1 set(s)
Net weight	8,74 kg
Gross weight	9,2 kg
Customs tariff number	73269098
ECLASS 8.0	27189261

# Tender text

## Multi-piece TS gland plate

For filling the base frame in a TS8 7 FR(i) enclosure, with gland plates and a cable entry sliding plate with rubber cable clamp strip. Furthermore, the kit can be combined with the vented gland plate modules and the modules for cable entry purposes.

Dimension: For enclosures (WxD) 800 x 1,000 mm

Material: Sheet steel, zinc-plated