


Rittal – The System.

Faster – better – everywhere.

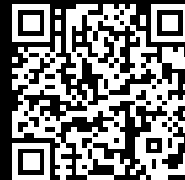

DK 7827.023

Depth stays as installation kit

State: 22/12/2025 (Source: [rittal.com/ro-ro](https://www.rittal.com/ro-ro))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7827.023 - Depth stays as installation kit for mounting angles, 482.6 mm (19"), mounting dimensions 23" and 24"

For mounting angles, 482.6 mm (19"), when using depth stays in 800 mm wide enclosures, attachment spacings of 23" and 24" are achieved, either cranked or L-shaped mounting angles may be used.

Features

Model No.	DK 7827.023
Design	Mounting dimension 23"
Product description	Installation in 800 mm wide enclosures: When using depth stays in 800 mm wide enclosures, attachment spacings of 23" and 24" are achieved. Either cranked or L-shaped, 482.6 mm (19") mounting angles may be used.
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
To fit	Width: 800 mm Depth: 1,000 mm
Note on Model No.	Extended delivery times.
Packs of	4 pc(s).
Net weight	0.72
Customs tariff number	73269098
EAN	4028177250345
ECLASS 8.0	27189261

Tender text

DK-TS depth stay, 23 inch

Material: Sheet steel, zinc-plated, passivated

Dimensions (W x H x D): 800 mm x 0 mm x 1000 mm