


Rittal – The System.

Faster – better – everywhere.

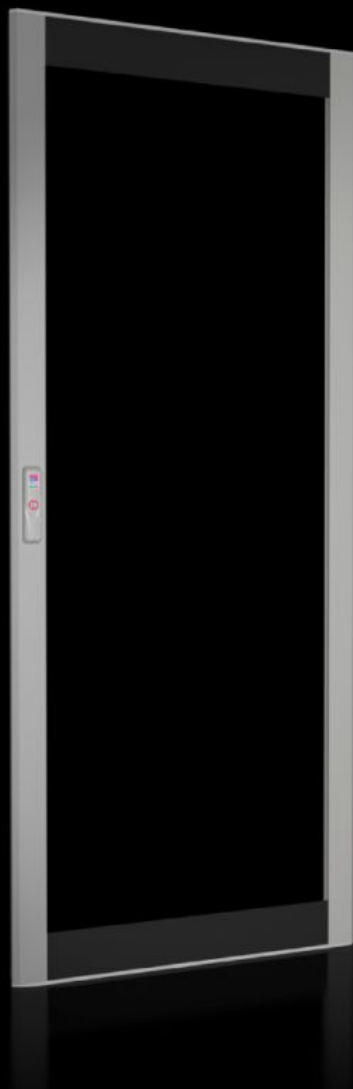

VX 8618.030 Glazed door

State: 07/08/2025 (Source: [rittal.com/ro-ro](https://www.rittal.com/ro-ro))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



VX 8618.030 - Glazed door for VX

Instead of a sheet steel door or rear panel.

Features

Model No.	VX 8618.030
Product description	Instead of a sheet steel door or rear panel.
Material	Frame: Extruded aluminium section Viewing window: Single-pane safety glass, 3 mm
Surface finish	Powder-coated
Colour	Frame: RAL 7035 Viewing window (printed mask on the inside): RAL 9005
Supply includes	Glazed door Locking rod with double-bit insert 180° hinges (4)
IK Code	IK08
Note	Lock components for frame 8618.110 are required when mounting instead of the rear panel
Type rating to UL 50E	Type 1 Type 12
IP protection category to IEC 60529	IP 55
To fit	Enclosure type: VX Width: = 800 mm Height: = 2,000 mm
Packs of	1 pc(s).
Net weight	16.5
Gross weight	17.4
Customs tariff number	94039910
EAN	4028177921009
ETIM 9	EC000747

Features

ECLASS 8.0	27182204
------------	----------

Approvals

Approvals	UL + C-UL - FTTA
Certificates	Protection category