
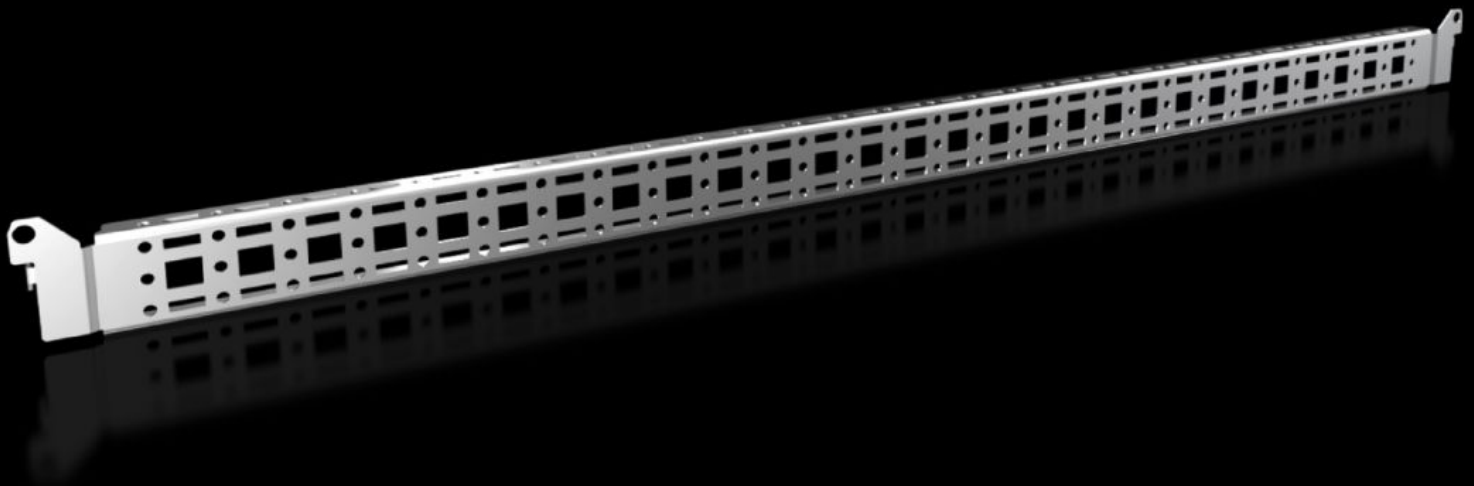


Rittal – The System.

Faster – better – everywhere.

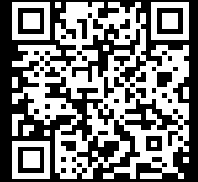

VX 8619.740

**Punched section with mounting
flange, 14 x 39 mm**

State: 19/06/2026 (Source: rittal.com/ro-ro)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



VX 8619.740 - Punched section with mounting flange, 14 x 39 mm for VX, VX SE, PC, IW, AX

For securing cable ducts, cable conduit holders, equipment installed on the door, etc.



Features

Model No.	VX 8619.740
Product description	For attaching cable ducts, cable conduit holders, equipment installed on the door, etc.
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
Distance between fixing points	775 mm
To fit door width	900 mm
VX SE installation options	In door width 900 mm
AX stainless steel installation options	In enclosure width 800 mm
Assembly instruction	For installation in AX sheet steel, only in conjunction with rail for interior installation AX
Note	For installing your own components on the punched section with mounting flange, metal screws or self-tapping M5 screws are required

Features

To fit	Enclosure type: VX SE AX stainless steel
Packs of	4 pc(s).
Net weight	1,564 kg
PCF per pack (cradle-to-gate)	12.06
Customs tariff number	73269098
ETIM 9	EC002620
ECLASS 8.0	27189234
Product description	VX Punched section, with mounting flange 14 x 39 mm, for door width: 900 mm

Approvals

Explanations	PCF-declaration
--------------	-----------------