


# Rittal – The System.

Faster – better – everywhere.

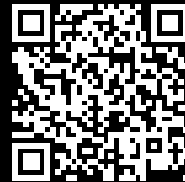

## TS 8801.120 Partial doors

State: 10/05/2025 (Source: [rittal.com/ro-ro](http://rittal.com/ro-ro))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TS 8801.120 - Partial doors for TS

Door may be optionally hinged on the right or left.



## Features

Model No.	TS 8801.120
Product description	Suitable for TS enclosures instead of a door or rear panel. The partial doors may be combined with one another as required. A trim panel is required at the top and bottom in each case. Door may be optionally hinged on the right or left. In the case of doors without viewing panel (height 600 – 1000 mm), monitor frame SZ 2305.000 may be installed. Standard double-bit lock insert may be exchanged for lock inserts, type F, and from 600 mm height, for comfort handle.
Material	Sheet steel, 2 mm
Colour	RAL 7035
Supply includes	Cross member Hinges Lock components Assembly parts
Dimensions	Width: 800 mm Height: 200 mm

# Features

IP protection category to IEC 60529	IP 54 for a completed enclosure
Packs of	1 pc(s).
Net weight	3.894
Gross weight	4.094
Customs tariff number	94039910
EAN	4028177250666
ETIM 9	EC000747
ECLASS 8.0	27182204