


Rittal – The System.

Faster – better – everywhere.

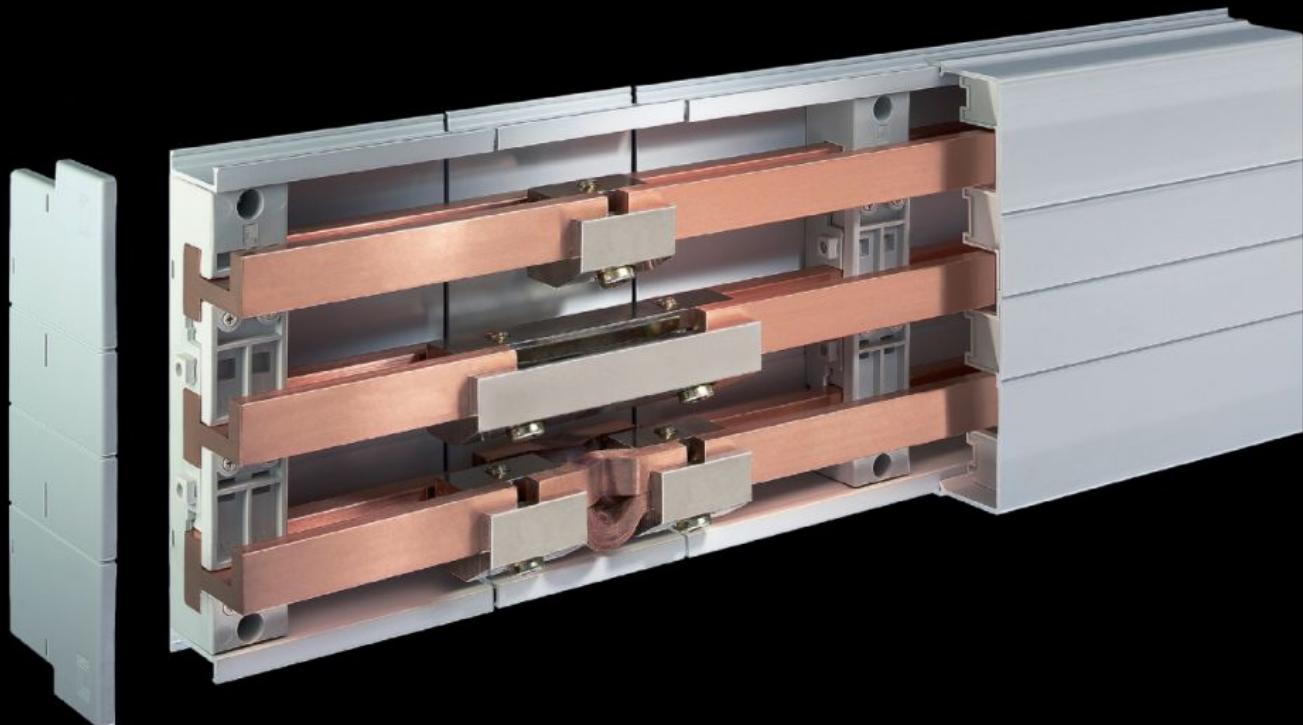

SV 9342.004

Busbar support PLS

State: 04/02/2026 (Source: rittal.com/ro-ro)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 9342.004 - Busbar support PLS

For PLS special busbars 800 A/1600 A, 3-pole and 4-pole, suitable for top-mounting.

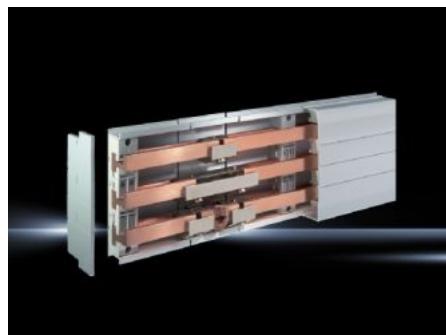

Features

Model No.	SV 9342.004
Material	Polyamide Fire protection corresponding to UL 94-V0
Colour	RAL 7035
Rated operating voltage	1000 V, 3~
Electrical ratings UL (SCCR)	65 kA - 480 V, support spacing 250 mm, PLS 1600 busbars, circuit breaker max. 1200 A, DIVQ/7
Note on Model No.	The use of a base tray is required for UL applications UL approval only applies in conjunction with AC application
Busbar support design	PLS 1600 PLUS
Number of poles	4-pole
To fit busbars	PLS 1600
Internal attachment	Yes
Centre-to-centre spacing of busbars	60 mm
Packs of	4 pc(s).
Net weight	2.2
Gross weight	2.321

Features

Customs tariff number	85469010
EAN	4028177536760
ETIM 9	EC001166
ECLASS 8.0	27400607

Approvals

Approvals	ABS Lloyds Register of Shipping UL + C-UL (listed)
Explanations	Declaration of conformity Declaration of conformity UK
