


**Rittal – The System.**

Faster – better – everywhere.

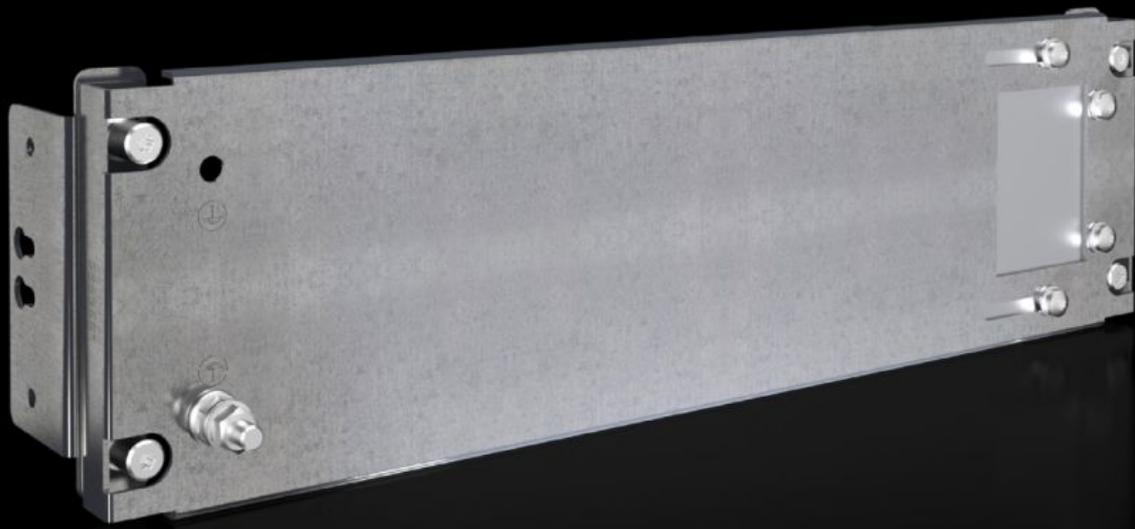

**SV 9683.561**

**Partial mounting plate**

State: 10/05/2026 (Source: [rittal.com/ro-ro](http://rittal.com/ro-ro))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SV 9683.561 - Partial mounting plate for compartment side panel

With or without duct, for direct attachment to the functional space side panel.

## Features

Model No.	SV 9683.561
Design	with gland made from insulating material
Product description	For direct attachment to the compartment side panel for internal compartmentalisation. Universal interior installation with switchgear and controlgear. Creation of additional mounting levels. In combination with compartment dividers and side panel, internal compartmentalisation in accordance with Form 1 to 4 is possible.
Material	Sheet steel, 2 mm
Surface finish	Zinc-plated
Supply includes	Angle brackets and assembly parts
For compartment height	150 mm
Dimensions	Width: 502 mm Height: 143 mm
To fit	Width: = 600 mm
Packs of	1 pc(s).
Net weight	1,76 kg
Gross weight	1,86 kg
PCF per pack (cradle-to-gate)	7.1 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	94039910
ETIM 9	EC000213
ECLASS 8.0	27400613

# Features

---

Product description	SV Partial mounting plate, WH: 502x143 mm, with duct, for VX (W: 600 mm)
---------------------	--

# Approvals

---

Explanations	Declaration of conformity UK
--------------	------------------------------