


**Rittal – The System.**

Faster – better – everywhere.

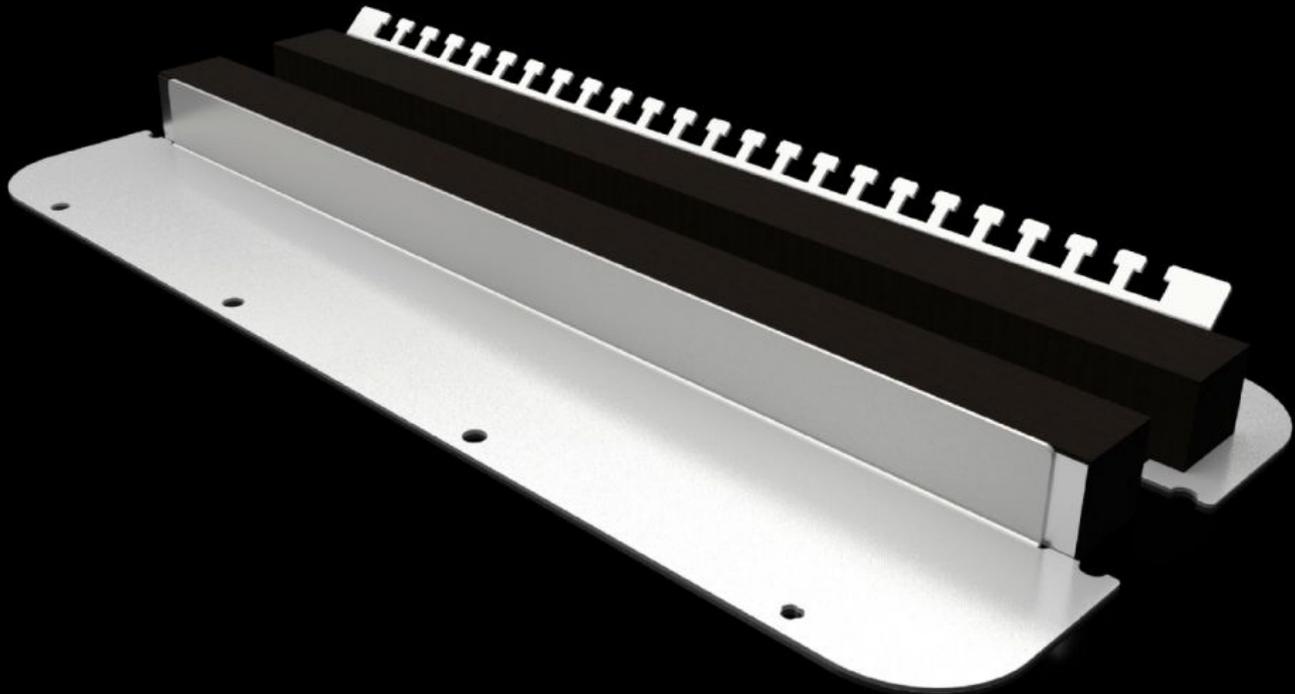

**SZ 2563.450**

**Two-part gland plate with foam  
rubber cable clamp strip**

State: 13/03/2026 (Source: [rittal.com/rs-sr](http://rittal.com/rs-sr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2563.450 - Two-part gland plate with foam rubber cable clamp strip for AX

The divided gland plate supports simple mounting on the enclosure and offers a range of different installation options. For simple insertion of cables with and without connectors into the enclosure. Special drilled holes in the gland plate ensure automatic potential equalisation during screw-fastening. Bolts, clips and earthing cables are no longer required.

## Features

Model No.	SZ 2563.450
Design	two-piece
Material	Sheet steel
Colour	RAL 7035
Supply includes	Assembly parts
Note	The allocation of gland plate sizes is indicated on the relevant enclosures When installing in enclosure width >760 mm, 2 packs are required
Dimensions	Width: 447 mm Depth: 149 mm
To fit	Enclosure type: AX
To fit Model No.	1050000 1057000 1100000
Gland plate	Size: 3
Packs of	1 pc(s).
Customs tariff number	73269098
ETIM 8	EC000211
ECLASS 8.0	27142421
Product description	SZ metal gland plate, two-part, for AX, with foam rubber cable clamp strip, WD: 447x149 mm, for size 3 gland plates