


Rittal – The System.

Faster – better – everywhere.

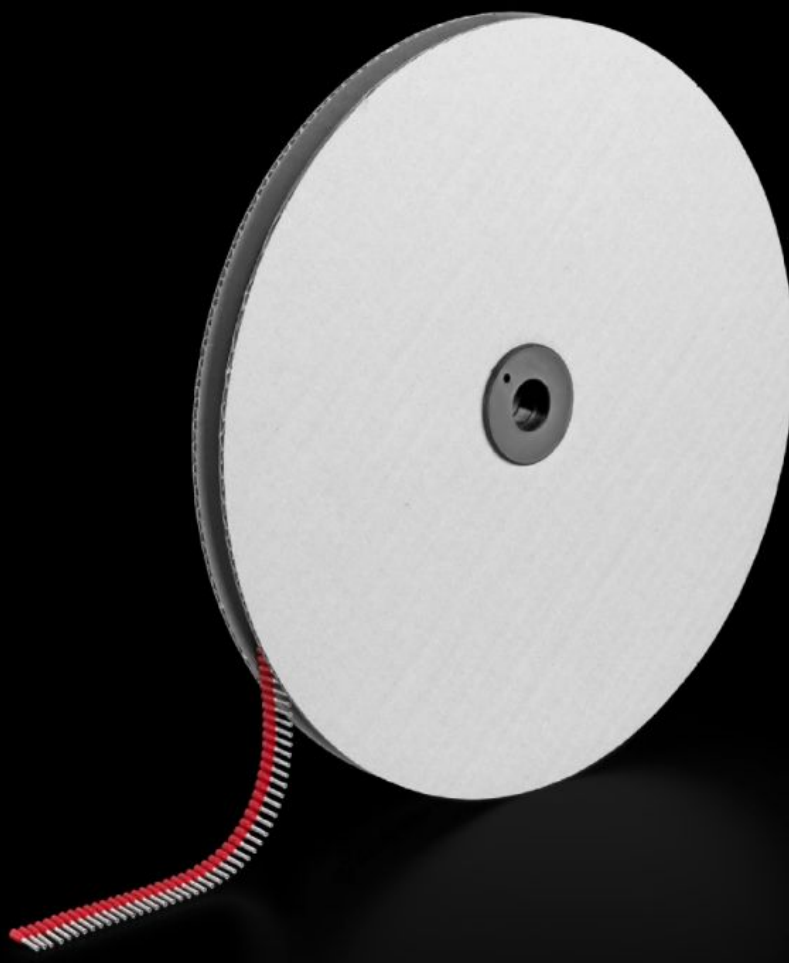

AS 4051.546 Wire end ferrules

State: 28/07/2026 (Source: [rittal.com/rs-sr](https://www.rittal.com/rs-sr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4051.546 - Wire end ferrules on a reel

With plastic collar.

Features

Model No.	AS 4051.546
Product description	With plastic collar.
Technical specifications	Heat-resistant to 105 °C
Material	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
Colour	Red
Length	10 mm
AWG	18
Internal diameter	3,5 mm
For cross-section	1 mm ²
DIN colour code	Yes
Multinorm	Yes
Note	UL-certified in conjunction with the relevant tools, such as crimping machines.
Delivery form	Taped
Packs of	4.000 pc(s).
Customs tariff number	85369010
ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290
Product description	Wire end ferrules 1.0 mm ² x 10 mm AWG 18 multinorm, packs of 4,000 pc(s)., colour: red, delivery form: on belt (in accordance with the DIN colour code), 1.0 mm ²

Approvals

Approvals

UL + C-UL (listed)