


# Rittal – The System.

Faster – better – everywhere.

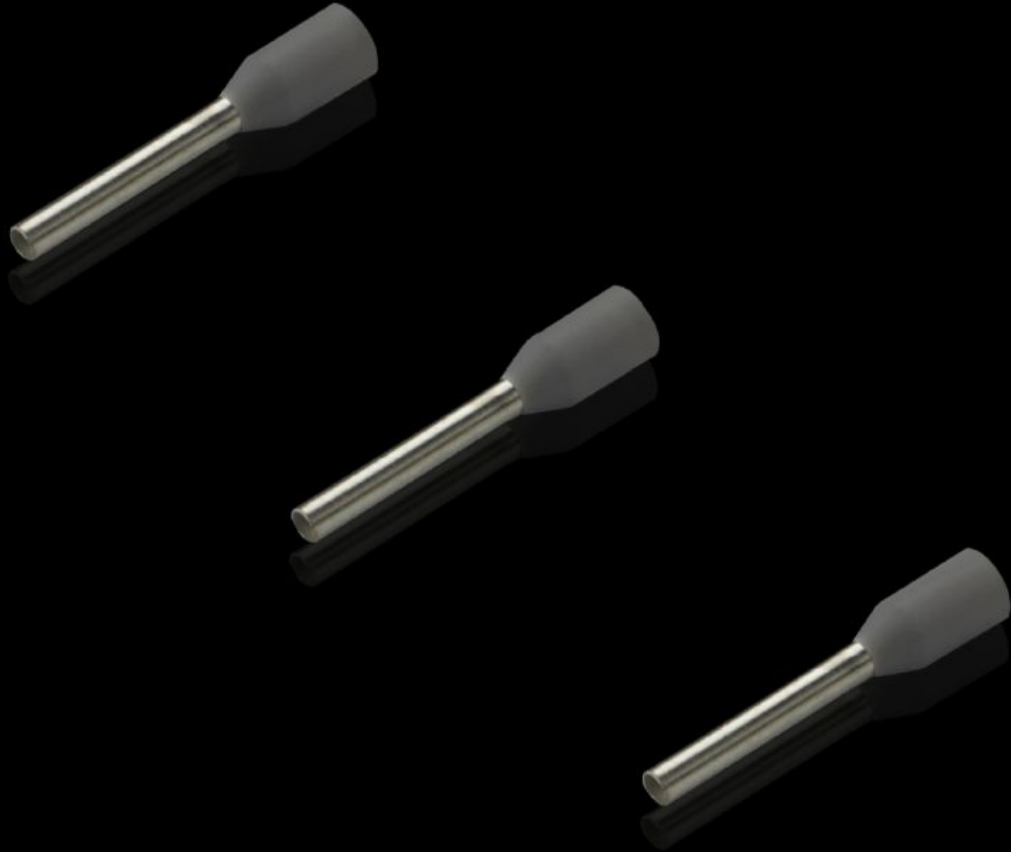

## AS 4051.641 Wire end ferrules

State: 19/06/2026 (Source: [rittal.com/rs-sr](http://rittal.com/rs-sr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4051.641 - Wire end ferrules loose

With plastic collar.

## Features

|                          |   |
|--------------------------|---|
| Model No.                | AS 4051.641   |
| Product description      | With plastic collar.  |
| Technical specifications | Heat-resistant to 105 °C  |
| Material                 | E-Cu, galvanic tin-plated<br>Plastic collar: Polypropylene  |
| Colour                   | Grey  |
| Length                   | 10 mm   |
| AWG                      | 18  |
| Internal diameter        | 2,8 mm  |
| For cross-section        | 0,75 mm <sup>2</sup>  |
| DIN colour code          | Yes   |
| Note                     | UL-certified in conjunction with the relevant tools, such as crimping machines.<br>For bespoke advice, please contact your Rittal sales consultant. |
| Standards                | AEH DIN 46228   |
| To fit Model No.         | 4051.205<br>4051.210  |
| Delivery form            | Loose (10 packs of 100)   |
| Packs of                 | 1.000 pc(s).  |
| Net weight               | 1 kg  |
| Gross weight             | 0,11 kg   |
| Customs tariff number    | 85369010  |
| ETIM 9                   | EC000005  |
| ETIM 8                   | EC000005  |

# Features

---

|                     |   |
|---------------------|---|
| ECLASS 8.0          | 36659290  |
| Product description | Wire end ferrules for wire processing, 0.75 mm <sup>2</sup> , AWG 18, grey, 10 mm, loose (10 packs of 100), 1000 pcs. |

---

# Approvals

---

|           |                          |
|-----------|--------------------------|
| Approvals | UL + C-UL (listed)<br>UR |
|-----------|--------------------------|