


**Rittal – The System.**

Faster – better – everywhere.

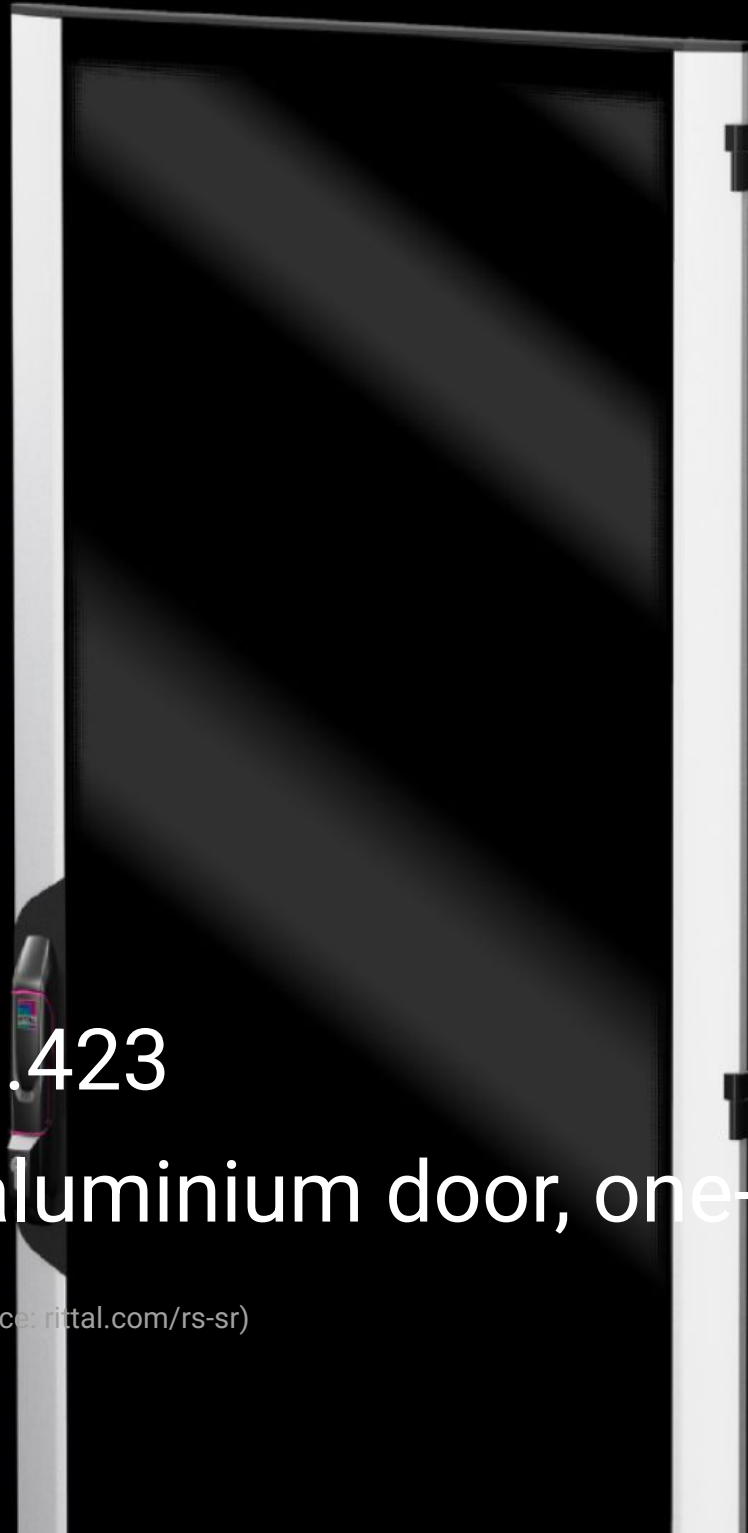

**VX 5301.423**

**Glazed aluminium door, one-piece**

State: 27/06/2026 (Source: [rittal.com/rs-sr](http://rittal.com/rs-sr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# VX 5301.423 - Glazed aluminium door, one-piece for VX IT

To replace existing doors.



## Features

Model No.	VX 5301.423
Product description	To replace existing doors.
Material	Frame: Extruded aluminium section Vertical extrusion: Aluminium, anodised Horizontal extrusion: Aluminium, spray finished Viewing window: Single-pane safety glass, 3 mm
Colour	Comfort handle VX, hinges, horizontal extrusion: RAL 9005 Vertical profile: silver coloured
Supply includes	Door with comfort handle VX for semi-cylinders with security lock 3524 E 3 x 180° hinges, fitted Assembly parts
Assembly instruction	For a door opening angle of 180° when baying, a 180° baying hinge is required
Note	Door opening angle for stand-alone siting: max. 240° Door opening angle when baying: max. 105°

# Features

IP protection category to IEC 60529	IP 55
To fit	Enclosure type: VX IT Width: = 800 mm Height: = 2,000 mm
Packs of	1 pc(s).
Net weight	16,142 kg
Gross weight	17,2 kg
PCF per pack (cradle-to-gate)	65.5 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	94039910
ETIM 9	EC000747
ECLASS 8.0	27182204
Product description	Aluminium glazed door, one-piece for VX IT, to replace existing doors. For enclosure width 800 mm, for enclosure height 2,000 mm, frame: extruded aluminium section