


Rittal – The System.

Faster – better – everywhere.

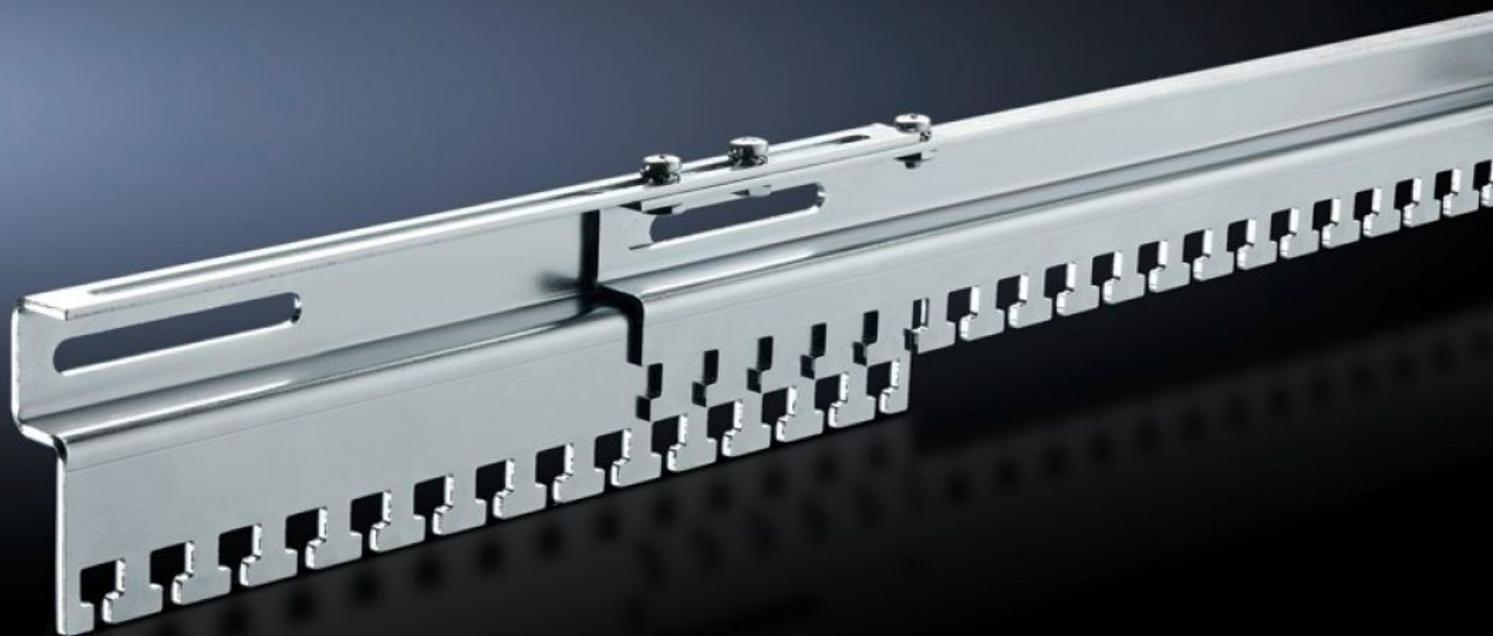

DK 7016.150

Cable clamp, variable

State: 01/03/2026 (Source: rittal.com/rs-sr)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7016.150 - Cable clamp, variable for enclosure-independent mounting

For enclosure-independent mounting, variable attachment from 450 to 800 mm for flexible cable clamping in two variants: as C rails or T-head rail.

Features

Model No.	DK 7016.150
Design	T-head rail
Product description	Variable attachment from 450 to 800 mm for flexible cable clamping in two variants. Supports attachment to punched sections with and without mounting flanges and direct screw-fastening onto mounting plates and other panels.
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
Packs of	1 pc(s).
Net weight	0,6 kg
Gross weight	1,043 kg
Customs tariff number	73269098
ETIM 9	EC002620
ECLASS 8.0	27189261
Product description	DK Cable clamp, variable, T-head rail, variable attachment from 450 to 800 mm

Tender text

Cable clamp, variable, T-head version

Cable clamp rail, length-adjustable, for flexible attachment irrespective of the enclosure system used.

Variable attachment of 450 - 800 mm.

The cable clamping occurs by means of fixing to T-heads.

Dimensions: L(mm): 450 - 800 mm

Sheet steel, zinc-plated, passivated