

**Rittal – The System.**

Faster – better – everywhere.



**DK 7153.005**

**Blanking panel, 482.6 mm (19")**

State: 22/05/2026 (Source: [rittal.com/rs-sr](http://rittal.com/rs-sr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7153.005 - Blanking panel, 482.6 mm (19")

As an extension cover or for population as required.

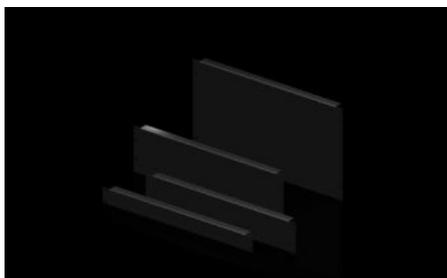

## Features

Model No.	DK 7153.005
Product description	As an extension cover or for population as required.
Material	Sheet steel
Colour	RAL 9005
Build-up height	132,5 mm
Note on Model No.	Extended delivery times.
Dimensions	Width: 482.6 mm
Units	3 U
Packs of	2 pc(s).
Net weight	1,56 kg
Gross weight	1,76 kg
PCF per pack (cradle-to-gate)	6.7 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	73269098
ETIM 9	EC000456
ECLASS 8.0	27189217
Product description	DK Blanking panel, 482.6 mm (19"), 3 U, Installation height: 132,5 mm, RAL 9005

# Tender text

482.6 mm (19") blind-panel, 3 U

Used as an extension cover or for fitting separately.

Installation height: 132.5 mm, 3 U

Version: Steel sheet

Spray-finish: RAL 9005

Dimensions (W x H x D): 483 mm x 132.5 mm x 23 mm