

Rittal – The System.

Faster – better – everywhere.



RX 9360.625

RiLineX CB component adaptor

State: 09/06/2026 (Source: rittal.com/rs-sr)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9360.625 - RiLineX CB component adaptor

RiLineX CB component adaptor (3-pole, max. 400 A) for 60 mm busbar systems. The device width is 145 mm. The "Universal" variant with U nuts offers maximum flexibility for switch mounting. The adaptor features tool-free snap-on mounting with semi-automatic adjustment of the bar thickness between 5 and 10 mm. The cable outlet is easily converted to the top or bottom to suit individual requirements.

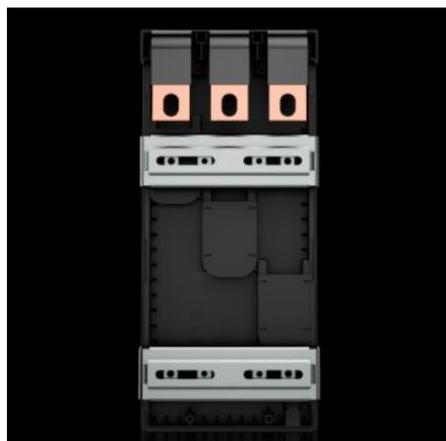

Features

| | |
|-------------------------------------|---|
| Model No. | RX 9360.625 |
| Design | universal |
| Benefits | Direct mounting of moulded-case circuit-breakers (MCCBs) on the board Snap-on mounting up to 250 A and simple adjustment to busbar thickness 5/10 mm Fast, simple pre-assembly of standard market switch types outside of the enclosure |
| Material | Polyamide (PA 6) Fire protection corresponding to UL 94 |
| Colour | RAL 9005 RAL 35745 |
| Supply includes | Including 3 connection space covers, 2 cross members and assembly parts |
| IP protection category to IEC 60529 | IP 2XB |

Features

| | |
|---|---|
| Rated impulse withstand voltage Uimp | 8 kV |
| Rated voltage | 690 V AC 600 V AC (UL) |
| Rated insulation voltage Ui | 1.000 V |
| Contamination level | 3 |
| Number of poles | 3-pole |
| Cable outlet | Top/bottom |
| Cross-section | 29 mm ² 10 mm ² |
| To fit manufacturer (model) | Our selection aid, available in the Downloads section, helps you to easily find a matching component adaptor. |
| To fit busbar system | RiLineX RiLine60 |
| Fundamental frequency | 50...60 Hz |
| Ambient humidity (non-condensing) | 10...90 % |
| To fit busbars | 15 x 5/10 20 x 5/10 30 x 5/10 |
| Operating temperature range | -25 °C...55 °C |
| Storage temperature range | -25 °C...75 °C |
| Dimensions | Width: 145 mm Height: 325.8 mm Depth: 76.4 mm |
| Packs of | 1 pc(s). |
| Net weight | 3,6 kg |
| Gross weight | 3,8 kg |
| Copper weight (kg per piece) | 1,652 |
| PCF per pack (cradle-to-gate) | 21.11 |

Features

| | |
|-----------------------|---|
| Customs tariff number | 85369095 |
| ETIM 9 | EC001531 |
| Product description | RiLineX CB component adaptor (3-pole, max. 400 A) for 60 mm busbar systems. The device width is 140 mm. The "Universal" variant with U nuts offers maximum flexibility for switch mounting. The adaptor features tool-free snap-on mounting. The cable outlet is easily converted to the top or bottom to suit individual requirements. |

Approvals

| | |
|--------------|--|
| Approvals | UL + C-UL (listed) |
| Explanations | Declaration of conformity PCF-declaration |

Tender text

RiLineX CB component adaptor (Universal Fix)

RiLineX CB component adaptor
for 60 mm busbar systems.

Fastening is carried out using u-nuts in
the two adjustable support rails.

For voltages up to 690 V AC and 690 V DC.

IEC and UL approved.

Product information

Number of poles: 3

Busbar dimensions: 15/20/30 mm x 5/10 mm

Rated current: 400 A

Connection: 174 mm²

Cable outlet: top/bottom

Dimensions: 145 mm x 325 mm x 76 mm (WxHxD)

Manufacturer: Rittal GmbH & Co. KG

Type: 9360625