


Rittal – The System.

Faster – better – everywhere.

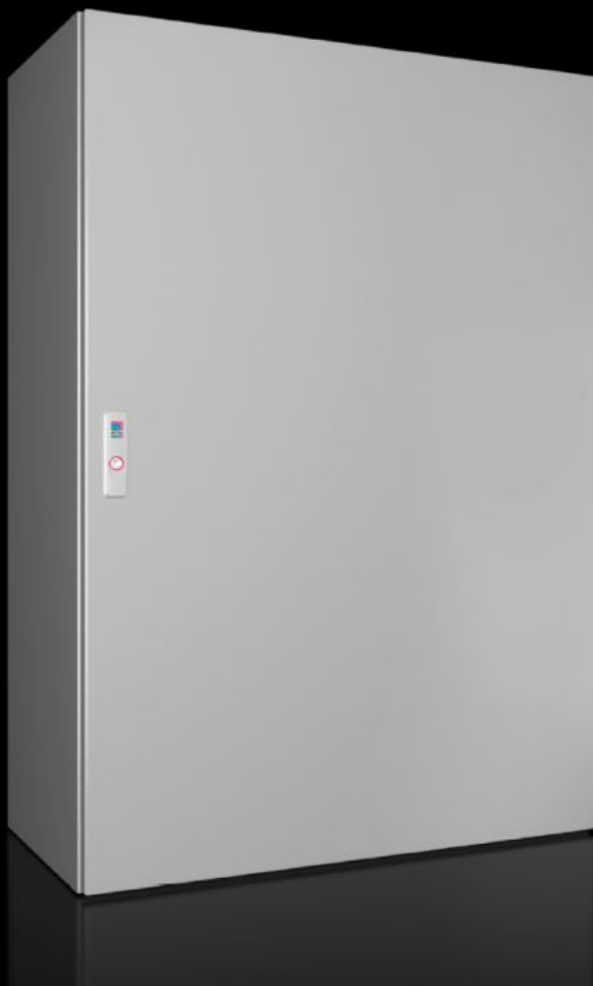

AX 1281.450

Kompaktapparatskåp AX

State: 2025-06-07 (Source: [rittal.com/se-sv](https://www.rittal.com/se-sv))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AX 1281.450 - Kompaktapparatskåp AX C4-H

The compact enclosure AX with integral enclosure locators in the roof, base and side forms the familiar 25 mm system pitch pattern from the VX25 large enclosure. System components and accessories are easily, quickly and securely installed and retrofitted on rails, with no drilling required. Surface coating to DIN EN ISO 12944 corrosion protection class C4-H. Important: Please observe the product properties and the notes on installation and maintenance in the product description.

Features

Art. nr.	AX 1281.450
Utförande	Surface coating to DIN EN ISO 12944
Fördelar	Fler inredningsmöjligheter genom integrerade höljesnockar med 25 mm-system-mallar i kombination med skenan för inredning och vår omfattande systemtillbehör Bevara skyddsarten (UL-godkännande) genom montering av skenan för inredning utan att borra Extra monteringsnivåer och högre bärlast genom golvinredningskena Enkel planering och konfiguration med Rittal Konfigurator RiPanel
Material	Skåp och dörr: Stålplåt Dörr: Stålplåt, omgivande inskummad PU-tätning
Ytbehandling	Enclosure and door: Powder-coated, textured paint Montageplåt: förzinkad
Färg	RAL 7035
Leveransens omfattning	Skåp med dörr(ar) Plåtfläns(ar) i botten Montageplåt Dörrhålslist Lås: 3 mm dubbellås

Features

Observera:	Installation and maintenance: DIN EN ISO 12944 refers to corrosion protection for steel structures (e.g. containers and bridges) and is thus only indirectly applicable to enclosures. The test criteria defined in this standard were nevertheless applied to the paint finishes of the C4-H enclosures. Our "paint finish equivalent to C4-H" thus satisfies all requirements of the standard in respect of the 720-hour salt spray mist test. Even so, corrosion can still occur on such sheet-steel enclosures. If the enclosure is installed in an environment where there is a risk of corrosion, the user must provide for regular maintenance and the prompt repairing of any paint damage. Depending on the application, the user may need to take suitable precautions as protection against environmental conditions at the place of installation, e.g. UV radiation.
Kapslingsklass NEMA	NEMA 1, 3R, 4, 12
Kapslingsklass IP enligt EN 60 529	IP 66
IK-kod	IK10
Dimension	Bredd: 800 mm Höjd: 1.200 mm Djup: 400 mm
Materialtjocklek dörr	2 mm
Materialtjocklek låda	1,5 mm
Materialtjocklek montageplåt	2,5 mm
Mått för montageplåt (B × H)	745 mm x 1.175 mm
Antal dörrar	1
Variabel dörrupphängning	Yes
Lås	Utförande för lås: 3-punkts lås Antal lås: 1 Låsinsats: 3 mm dubbellås
Plåtfläns	Storlek: 5 Antal: 2
Grundmaterial	Stålplåt
Förpackningsenhet	1 st.
PCF per pack (cradle-to-gate)	223,8 kg CO2 eq (Cat B)

Features

Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
EAN	4028177993808
ETIM 9	EC000261
ETIM 8	EC000261
ECLASS 8.0	27180101