


Rittal – The System.

Faster – better – everywhere.

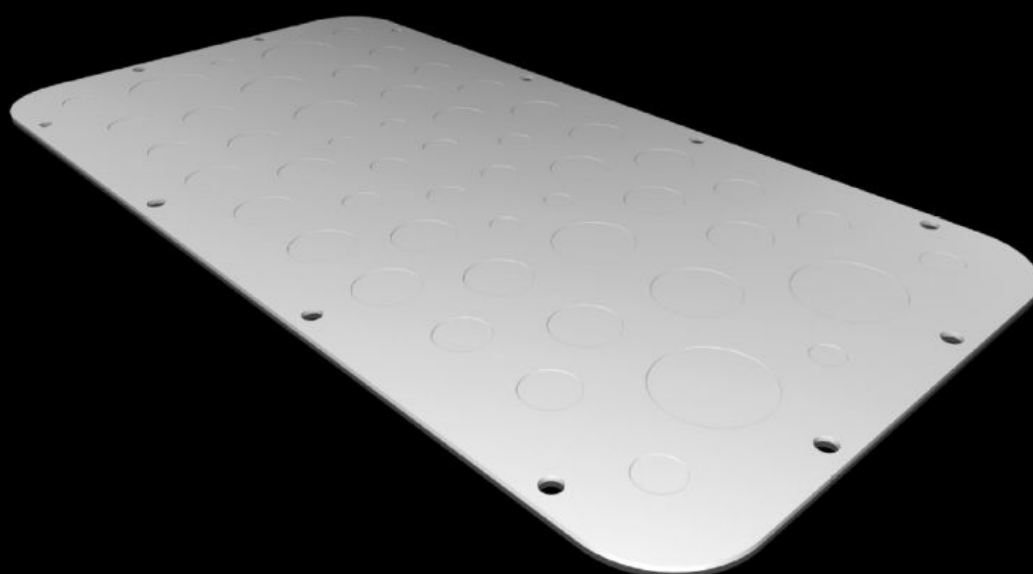

AX 2577.100 Plåtfläns i metall

State: 2025-04-27 (Source: [rittal.com/se-sv](https://www.rittal.com/se-sv))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AX 2577.100 - Plåtfläns i metall med metrisk förprägling, för AX

Hål för kabelförskruvningar slås lätt ut med en skruvmejsel.

Features

Art. nr.	AX 2577.100
Produktbeskrivning	Hål för kabelförskruvningar slås lätt ut med en skruvmejsel.
Material	Stålplåt
Färg	RAL 7035
Observera:	Tilldelningen av flänsarnas storlek anges vid respektive låda
Antal metriska förpräglingar	6 x M12 10 x M16 8 x M20 20 x M25 4 x M32 4 x M40
Dimension	Bredd: 436 mm Djup: 221 mm
Passar för	Skåptyp: AX
Plåtfläns	Storlek: 7
Kapslingsklass IP enligt EN 60 529	IP 66 vid korrekt montage
Typklassning motsvarande UL 50E	Typ 1 Type 12K
Number knockouts	6 10 8 20 4 4

Features

Metric diameter	M12 M16 M20 M25 M32 M40
Förpackningsenhet	1 st.
Nettovikt	1.136
Bruttovikt	1.146
PCF per pack (cradle-to-gate)	5,9 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Tullvarukod	73269098
EAN	4028177925267
E-Number Sweden	E3465301
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421

Approvals

Approvals	UL + C-UL - FTTA
-----------	------------------