
 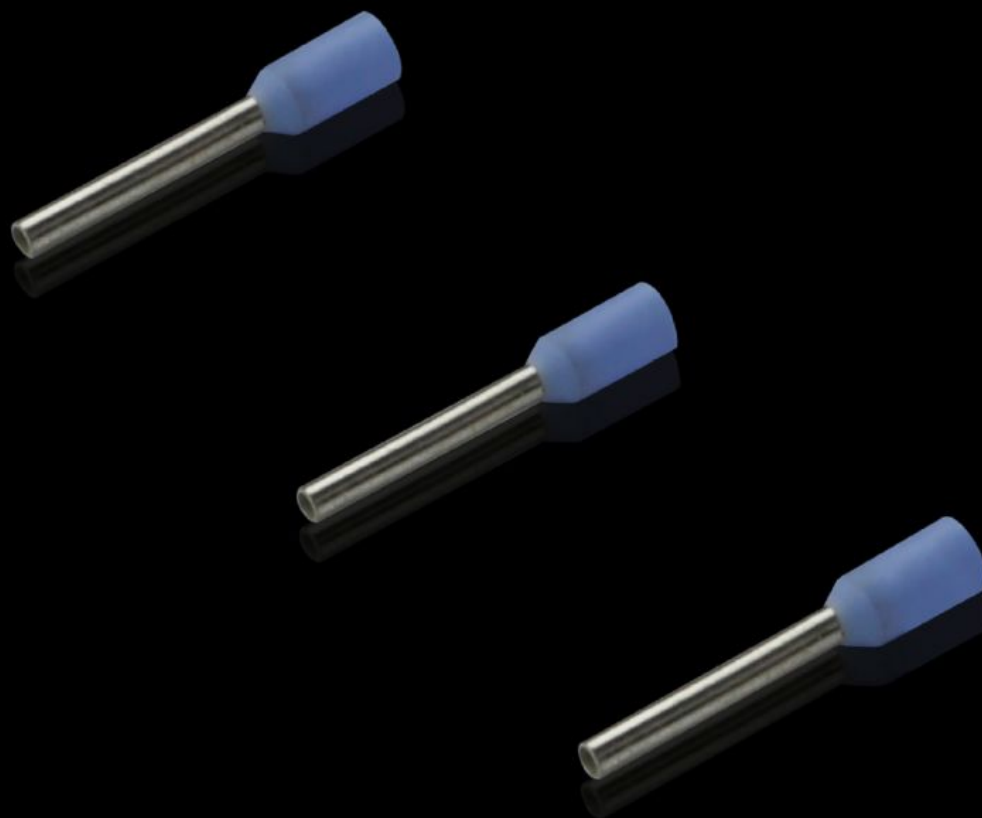


Rittal – The System.

Faster – better – everywhere.



AS 4050.754 Ändhylsor

State: 2026-07-08 (Source: [rittal.com/se-sv](https://www.rittal.com/se-sv))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4050.754 - Ändhylsor lös

Med plastkragar.

Features

Art. nr.	AS 4050.754
Produktbeskrivning	Med plastkragar.
Tekniska data	Värmetålig upp till 105 °C
Material	E-Cu, galvaniskt förzinkad Plastkrage: Polypropylen
Färg	ljusblå
Längd	8 mm
AWG	24
Inre diameter	1,8 mm
Rittal-färgkod	Yes
För tvärsnitt	0,25 mm ²
Observera:	UL-certifierad i kombination med motsvarande verktyg, som t.ex. crimpmaskin. Kontakta din Rittal-rådgivare för enskild konsultation.
Standarder	AEH DIN 46228
Levererat utförande	lös
Förpackningsenhet	500 st.
Nettovikt	0,5 kg
Bruttovikt	0,026 kg
Tullvarukod	85369010
ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290

Features

Produktbeskrivning

Wire end ferrules for manual preassembly, 0.25 mm², AWG 24, 8 mm, light blue, loosely packed, 500 pc(s).

Approvals

Approvals

UL + C-UL (listed)
UR