


# Rittal – The System.

Faster – better – everywhere.

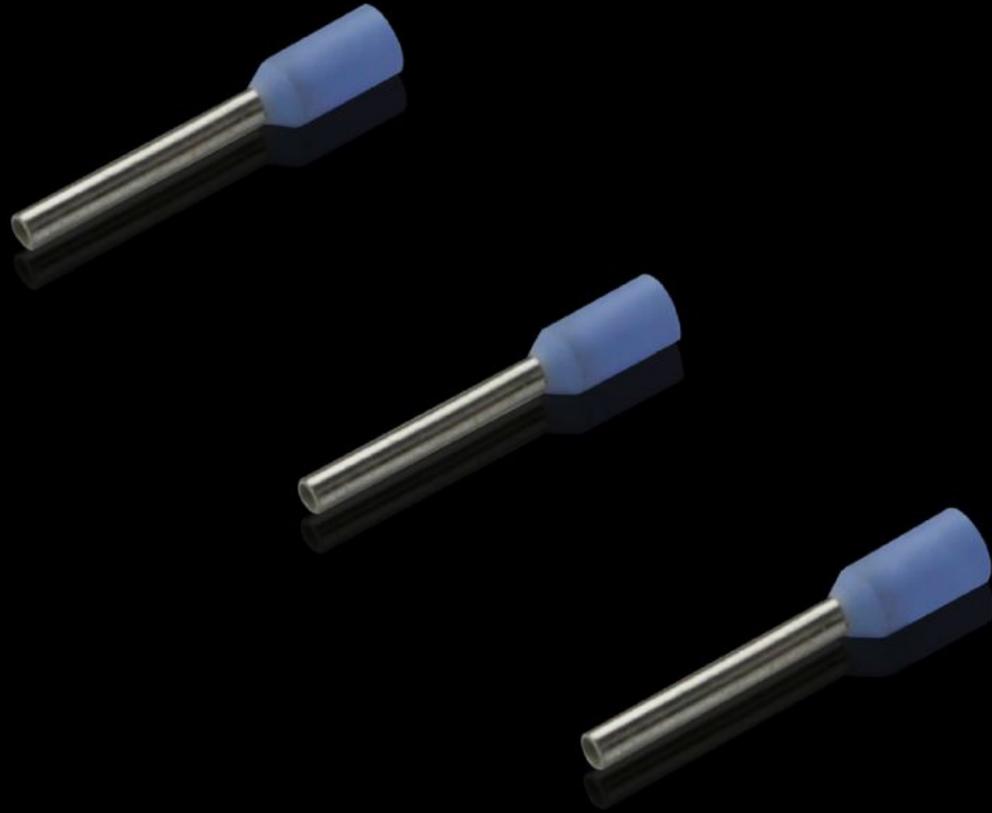

## AS 4050.754

## Ändhylsor

State: 2026-04-17 (Source: [rittal.com/se-sv](https://www.rittal.com/se-sv))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.754 - Ändhylsor lös

Med plastkragar.

## Features

Art. nr.	AS 4050.754
Produktbeskrivning	Med plastkragar.
Tekniska data	Värmetålig upp till 105 °C
Material	E-Cu, galvaniskt förzinkad Plastkrage: Polypropylen
Färg	ljusblå
Längd	8 mm
AWG	24
Inre diameter	1,8 mm
Rittal-färgkod	Yes
För tvärsnitt	0,25 mm <sup>2</sup>
Observera:	UL-certifierad i kombination med motsvarande verktyg, som t.ex. crimpmaskin. Kontakta din Rittal-rådgivare för enskild konsultation.
Standarder	AEH DIN 46228
Levererat utförande	lös
Förpackningsenhet	500 st.
Nettovikt	0,5 kg
Bruttovikt	0,026 kg
Tullvarukod	85369010
ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290

# Features

---

Produktbeskrivning

Wire end ferrules for manual preassembly, 0.25 mm<sup>2</sup>, AWG 24, 8 mm, light blue, loosely packed, 500 pc(s).

# Approvals

---

Approvals

UL + C-UL (listed)  
UR