


# Rittal – The System.

Faster – better – everywhere.

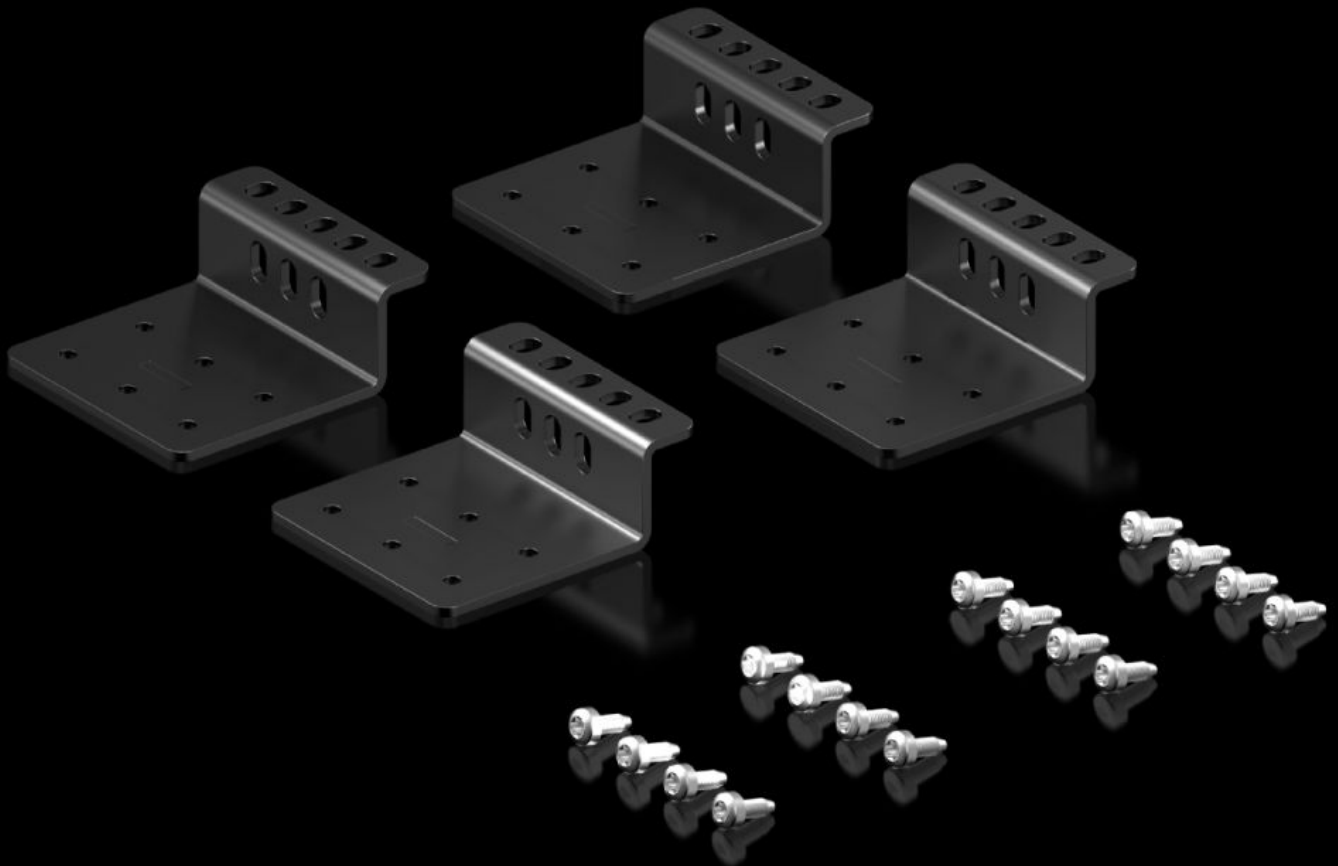

## VX 5302.160 Montagevinkel

State: 2026-04-12 (Source: [rittal.com/se-sv](https://www.rittal.com/se-sv))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# VX 5302.160 - Montagevinkel för VX IT 19"-profilskenor

Mounting bracket for mounting 482.6 mm (19") mounting angles in VX IT network/server racks.

## Features

Art. nr.	VX 5302.160
Utförande	för VX IT 19"-profilskena dynamic
Produktbeskrivning	För infästning av profilskenor med tummått i VX IT nätverks-/serverskåp.
Fördelar	En potentialutjämning för profilskenorna sker direkt via infästningen
Material	Stålplåt
Ytbehandling	Lackerad
Färg	RAL 9005
Leveransens omfattning	Inkl. fastsättningsmaterial
Passar för	Bredd: = 600 mm
Förpackningsenhet	4 st.
Nettovikt	0,68 kg
Bruttovikt	0,793 kg
PCF per paket (Cradle-to-Gate)	3,1 kg CO2 eq (Cat B)
Information om PCF-klass	Kategori B: PCF-värde (Cradle-to-Gate) på basis av produktens vikt ungefärligt beräknat och självdeklarerat
Tullvarukod	73182900
ETIM 9	EC002620
ECLASS 8.0	27189261
Produktbeskrivning	Montagevinkel för VX IT 19"-profilskenor, dynamic, för infästning av profilskenor med tummått i VX IT nätverks-/serverskåp. Fastsättning sker direkt på ramstativet för rack med 600 mm bredd

# Approvals

---

Explanations

Tillverkarens deklARATION