

Rittal – The System.

Faster – better – everywhere.



DK 7859.080 PSM Zero-U-Space

State: 2026-06-04 (Source: [rittal.com/se-sv](https://www.rittal.com/se-sv))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7859.080 - PSM Zero-U-Space

Modulär PDU för platssparande integrering i Zero-U-Space mellan sidogavel och 19"-montageplan i 800 mm breda IT-rack.

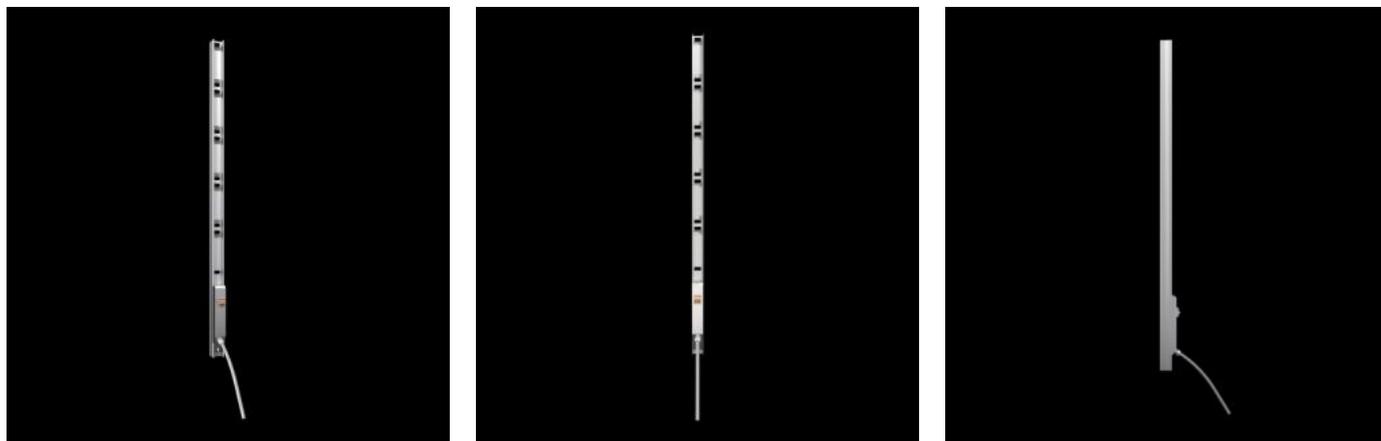

Features

Art. nr.	DK 7859.080
Produktbeskrivning	Modulär PDU för platssparande montage i Zero-U-Space utrymmet mellan sidogavel och 19"-profil i 800 mm breda IT-rack.
Material	Aluminiumprofil, natureloxerad
Längd	1 695 mm
Anslutningstyp (elektrisk)	Wago-uttag X-COM
Antal	2
Faser per inmatning	3~
Märkström (max.)	16 A
Modul-kontaktplatser (max.)	6
Kapslingsklass IP enligt IEC 60 529	IP 20
Montagekrav	Diverse anslutningskablar, även för 1-fasig anslutning
Dimension	Längd: 1.695 mm
Passar för	Skåptyp: VX IT Höjd: ≥ 2.000 mm

Features

Driftstemperatur	5 °C...45 °C
Luftfuktighet (ej kondenserande)	10...90 %
Förpackningsenhet	1 st.
Nettovikt	2,5 kg
Bruttovikt	2,8 kg
Tullvarukod	85369001
ETIM 9	EC002762
ECLASS 8.0	27371306
Produktbeskrivning	DK modular PDU, PSM busbar, modular power distribution for vertical installation, in the Zero-U-Space for 800 mm wide IT racks, 3~, 16 A, length 1695 mm, module slots: 6, infeeds: 2, connection: WAGO socket, x -COM, for enclosure height 2000 mm, aluminium section, natural anodised

Approvals

Explanations	Konformitetsförklaring
--------------	------------------------