


**Rittal – The System.**

Faster – better – everywhere.

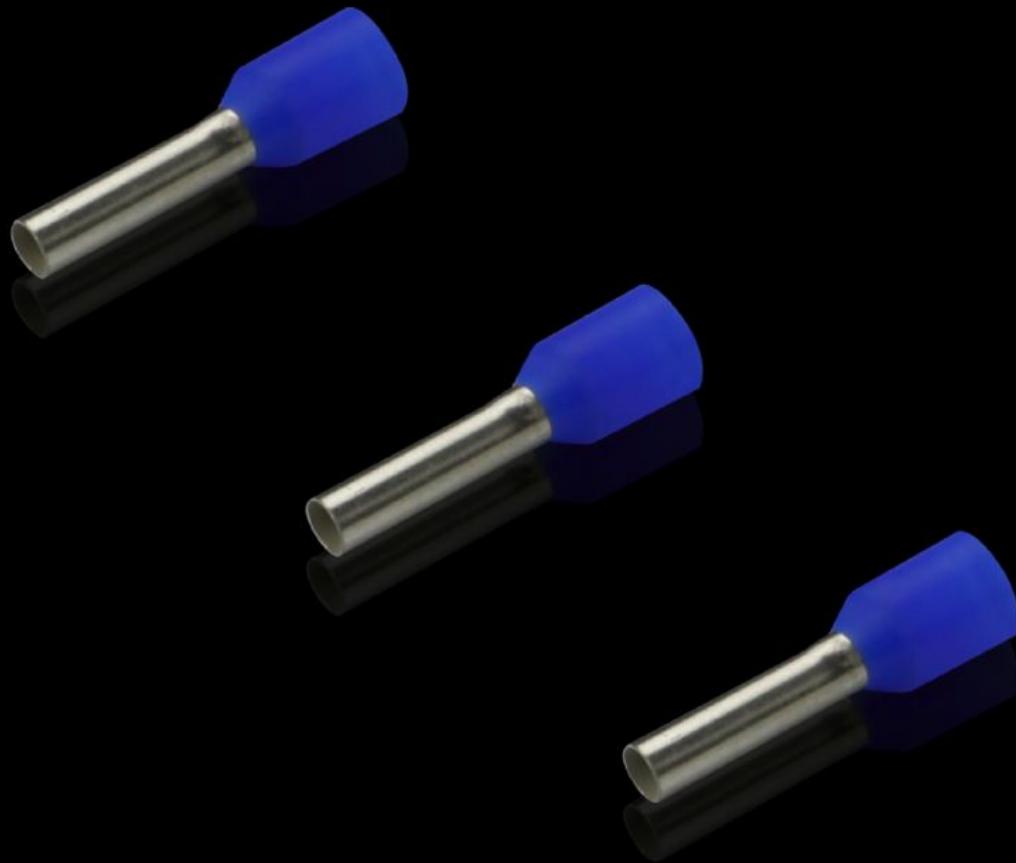

# AS 4051.525

## Wire end ferrules

State: 13/02/2026 (Source: [rittal.com/sg-en](http://rittal.com/sg-en))

# AS 4051.525 - Wire end ferrules loose

With plastic collar.

## Features

|                          |   |
|--------------------------|---|
| Model No.                | AS 4051.525   |
| Product description      | With plastic collar.  |
| Technical specifications | Heat-resistant to 105 °C  |
| Material                 | E-Cu, galvanic tin-plated<br>Plastic collar: Polypropylene  |
| Colour                   | Blue  |
| Length                   | 10 mm   |
| AWG                      | 14  |
| Internal diameter        | 4.2 mm  |
| For cross-section        | 2.5 mm <sup>2</sup>   |
| DIN colour code          | Yes   |
| Note                     | UL-certified in conjunction with the relevant tools, such as crimping machines.<br>For bespoke advice, please contact your Rittal sales consultant. |
| Standards                | AEH DIN 46228   |
| To fit Model No.         | 4051.205<br>4051.210  |
| Delivery form            | Loose (10 packs of 100)   |
| Packs of                 | 1,000 pc(s).  |
| Net weight               | 1   |
| Gross weight             | 0.176   |
| Customs tariff number    | 85369010  |
| EAN                      | 4028177815834   |
| ETIM 9                   | EC000005  |

# Features

---

ETIM 8 EC000005

---

ECLASS 8.0 36659290

# Approvals

---

Approvals UL + C-UL (listed)  
UR