


Rittal – The System.

Faster – better – everywhere.

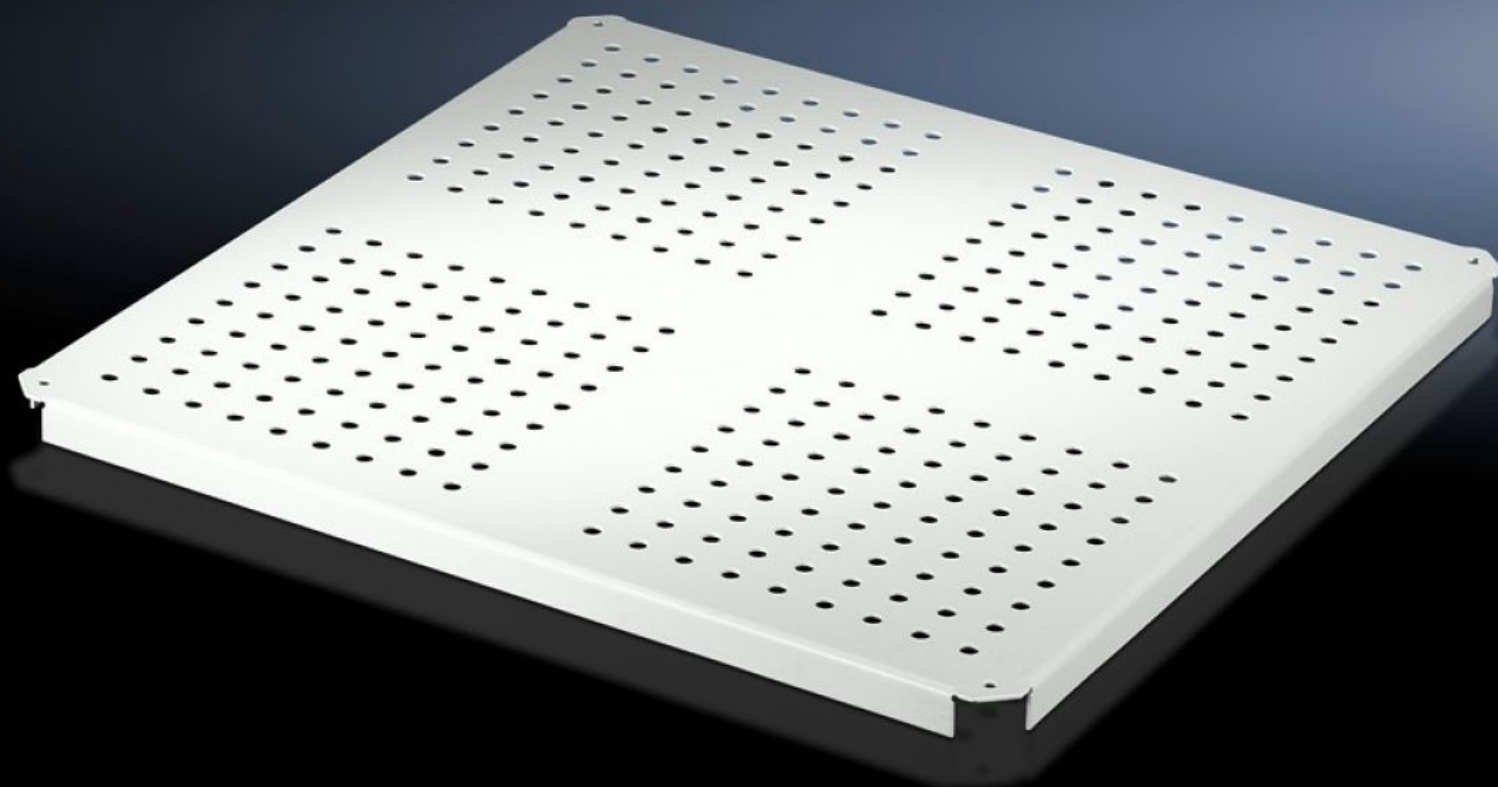

DK 7828.660

Component shelf, static installation

State: 17/12/2025 (Source: rittal.com/sg-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7828.660 - Component shelf, static installation for TS 8

Locate the mounting pieces in the frame and attach the component shelf, enclosure width: 600 and 800 mm, load capacity: 75 kg.

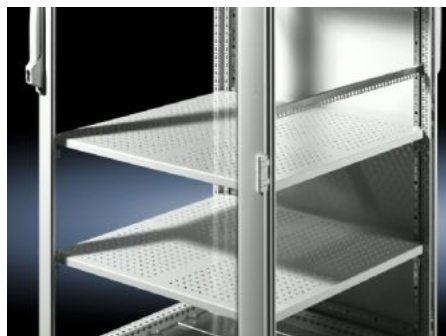

Features

| | |
|---------------------|---|
| Model No. | DK 7828.660 |
| Product description | Locate the mounting pieces in the frame and attach the component shelf. Attachment in the TS enclosure section offers the greatest possible support surface. Dimensions: Height 25 mm, width: Enclosure width minus 44 mm, depth: Enclosure depth minus 44 mm |
| Material | Sheet steel |
| Colour | RAL 7035 |
| Supply includes | Assembly parts |
| Load capacity | 75 kg surface load, static |
| Note | Combined use with vertically divided doors is not possible. Not suitable for combination with telescopic slides. |
| Dimensions | Width: 556 mm Height: 25 mm Depth: 556 mm |
| To fit | Enclosure type: TS 8 Width: 600 mm Depth: 600 mm |
| Packs of | 1 pc(s). |

Features

| | |
|-----------------------|---------------|
| Net weight | 6.151 |
| Gross weight | 6.475 |
| Customs tariff number | 94039910 |
| EAN | 4028177235199 |
| ECLASS 8.0 | 27189261 |

Tender text

Component shelf for static installation

Component shelf for static installation to enclosure frame

The component shelf is mounted directly inside the frame section edge folds using special mounting pieces, which enable the maximum area to be used.

Easy and secure fitting due to the plug-and-play technology.

The component shelf uses ventilation slots, which ensures economical air exchange between the separate layers.

Load capacity: 75 kg surface load

Material: Sheet steel

Spray finish: RAL 7035

for enclosure dimensions: W: 600 mm D: 600 mm