


Rittal – The System.

Faster – better – everywhere.

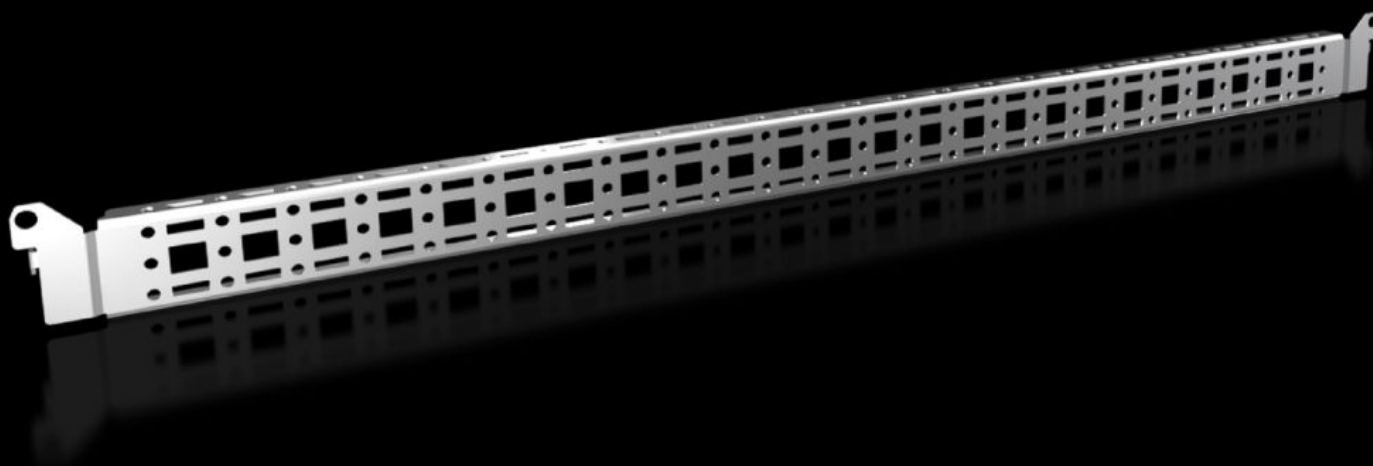

VX 8619.760

Punched section with mounting flange, 14 x 39 mm

State: 25/08/2025 (Source: rittal.com/sg-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



VX 8619.760 - Punched section with mounting flange, 14 x 39 mm for VX, VX SE, PC, IW, AX

For securing cable ducts, cable conduit holders, equipment installed on the door, etc.



Features

| | |
|--------------------------------|---|
| Model No. | VX 8619.760 |
| Product description | For attaching cable ducts, cable conduit holders, equipment installed on the door, etc. |
| Material | Sheet steel |
| Surface finish | Zinc-plated |
| Supply includes | Assembly parts |
| Distance between fixing points | 575 mm |
| AX installation options | In enclosure width 600 mm and in enclosure height 700 mm, in conjunction with rail for interior installation AX |
| Assembly instruction | For installation in AX sheet steel, only in conjunction with rail for interior installation AX |
| Note | For installing your own components on the punched section with mounting flange, metal screws or self-tapping M5 screws are required |
| To fit | Enclosure type: AX Suitable for width or height or depth: 700 mm |
| Packs of | 4 pc(s). |

Features

| | |
|-----------------------|---------------|
| Net weight | 1.2 |
| Gross weight | 1.374 |
| Customs tariff number | 73269098 |
| EAN | 4028177926851 |
| E-Number Sweden | E3465284 |
| ETIM 9 | EC002620 |
| ECLASS 8.0 | 27189234 |