
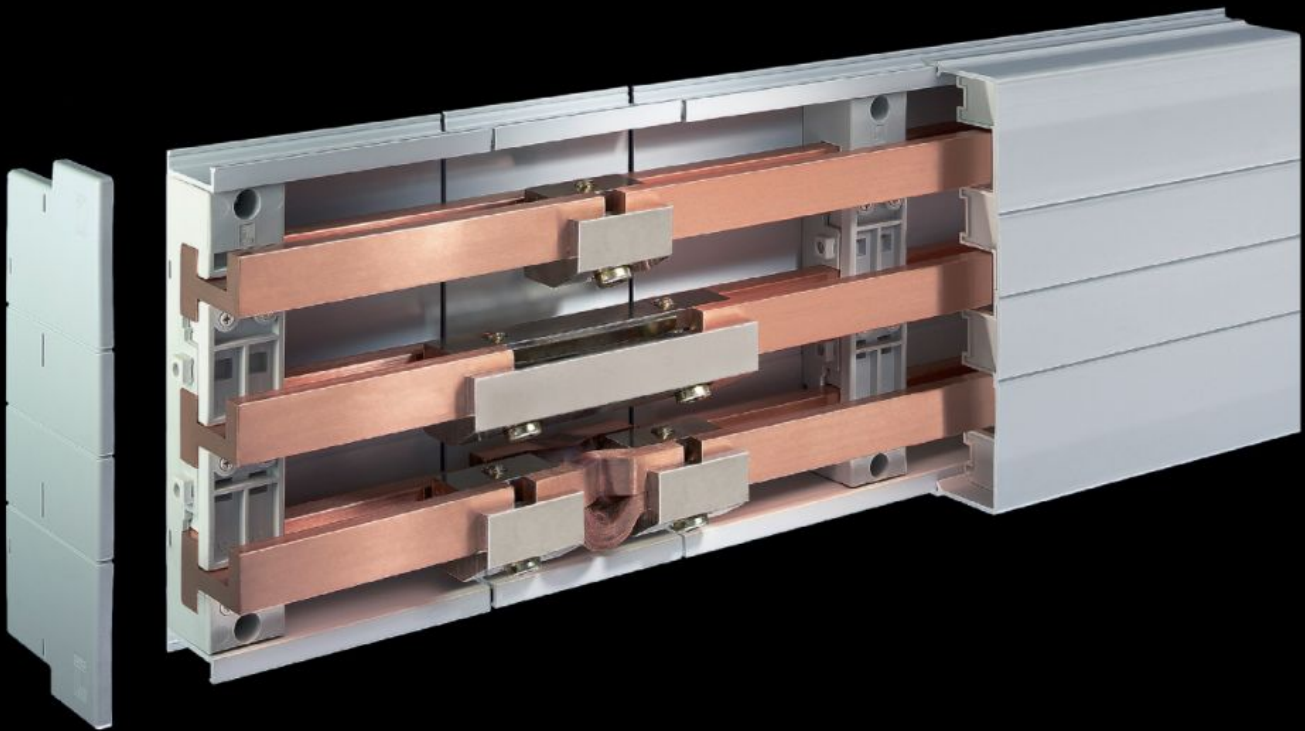


**Rittal – The System.**

Faster – better – everywhere.

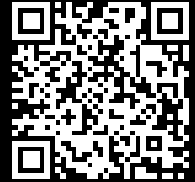

# SV 9342.004

## Busbar support PLS

State: 10/06/2026 (Source: [rittal.com/sg-en](http://rittal.com/sg-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SV 9342.004 - Busbar support PLS

For PLS special busbars 800 A/1600 A, 3-pole and 4-pole.

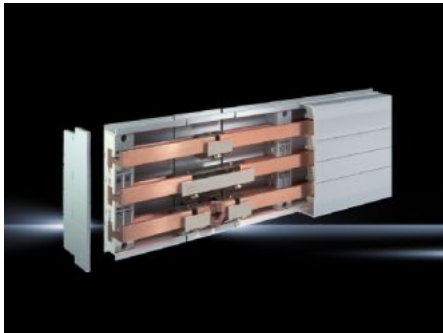

## Features

Model No.	SV 9342.004
Material	Polyamide Fire protection corresponding to UL 94-V0
Colour	RAL 7035
Rated operating voltage	1000 V, 3~
Electrical ratings UL (SCCR)	65 kA - 480 V, support spacing 250 mm, PLS 1600 busbars, circuit breaker max. 1200 A, DIVQ/7
Note on Model No.	The use of a base tray is required for UL applications UL approval only applies in conjunction with AC application
Busbar support design	PLS 1600 PLUS
Number of poles	4-pole
To fit busbars	PLS 1600
To fit Model No.	3516.000 3527.000 3528.010 3529.000
Internal attachment	Yes
Centre-to-centre spacing of busbars	60 mm

# Features

---

Approvals	UL
Packs of	4 pc(s).
Net weight	2.2 kg
Gross weight	2.321 kg
Customs tariff number	85469010
ETIM 9	EC001166
ECLASS 8.0	27400607
Product description	SV Busbar support, PLS 1600, 4-pole, 60 mm bar centre distance, UL design

# Approvals

---

Approvals	ABS Lloyds Register UL + C-UL (listed)
Explanations	Declaration of conformity Declaration of conformity UK