


**Rittal – The System.**

Faster – better – everywhere.

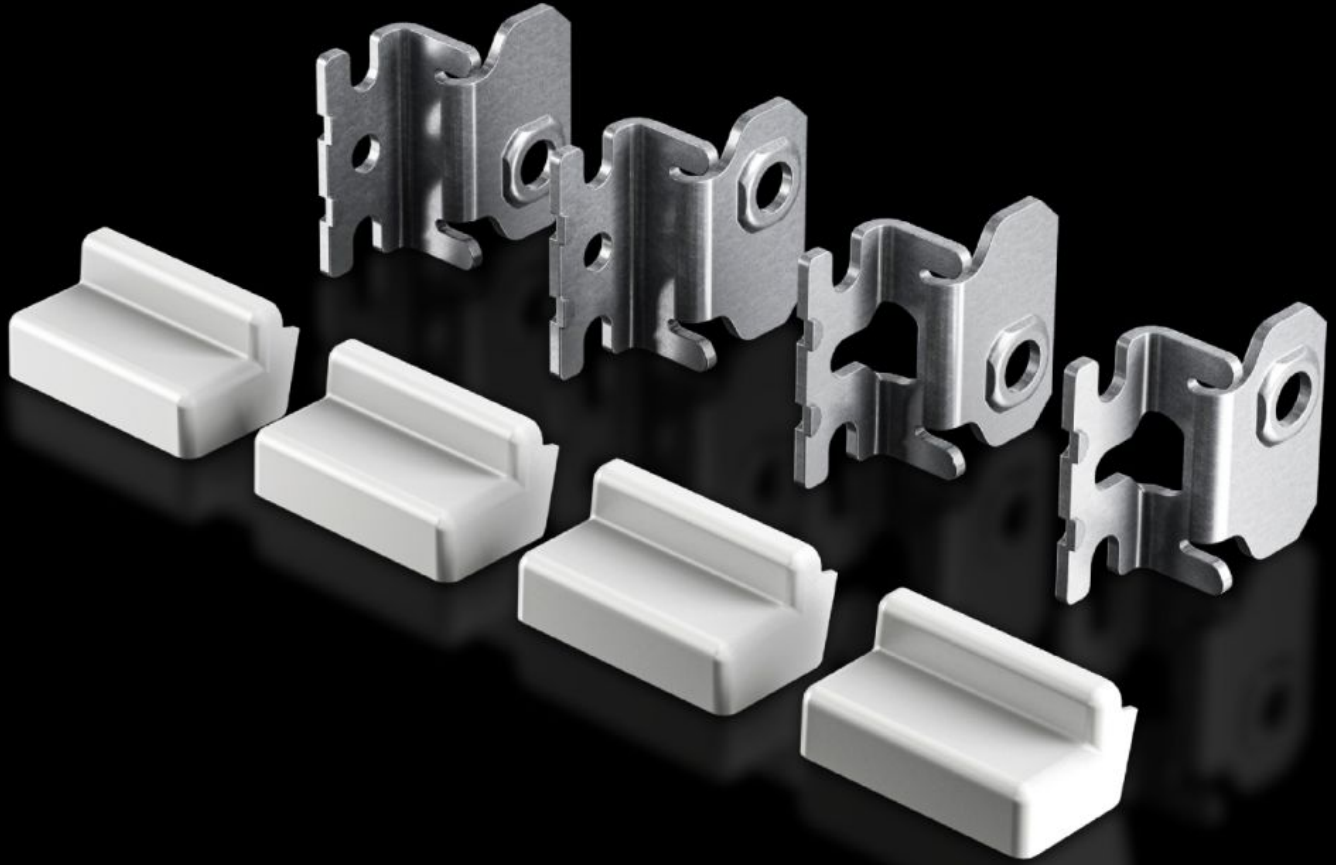

**AX 2508.020**

**Wall mounting bracket**

State: 4.12.2025 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AX 2508.020 - Wall mounting bracket for AX sheet steel, KX sheet steel, AX IT, EL

Ideal for convenient one-person assembly of wall-mounted enclosures, even in confined spaces.

## Features

|                       |  |
|-----------------------|--|
| Model No.             | AX 2508.020  |
| Product description   | Ideal for convenient one-person assembly of wall-mounted enclosures, even in confined spaces.  |
| Benefits              | <p>Screw-fastened directly from the rear with a self-tapping screw into the enclosure eyelet</p> <p>Simply suspend the wall-mounted bracket from a screw in the wall</p> <p>Different mounting positions allow the wall mounting bracket to be tailored to local conditions on site.</p> <p>As an alternative to the self-tapping screw, the support may also be secured from the inside using a screw and nut</p> <p>Additional option of attaching with a nut for dynamic applications</p> |
| Material              | Sheet steel, zinc-plated   |
| Supply includes       | Wall mounting bracket<br>Cover cap<br>Assembly parts   |
| Wall distance         | 20 mm  |
| To fit                | Enclosure type: AX sheet steel<br>KX sheet steel<br>AX IT<br>EL<br>AX wall-mounted enclosure, 3-part   |
| Type rating to UL 50E | Type 1<br>Type 3R<br>Type 4<br>Type 12   |
| Packs of              | 4 pc(s).   |
| Net weight            | 0.44   |

# Features

---

|                               |  |
|-------------------------------|--|
| Gross weight                  | 0.44   |
| PCF per pack (cradle-to-gate) | 1.7 kg CO2 eq (Cat B)  |
| Note on PCF category          | Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared |
| Customs tariff number         | 83025000   |
| EAN                           | 4028177938281  |
| E-Number Sweden               | E3465271   |
| ETIM 9                        | EC002625   |
| ETIM 8                        | EC002625   |
| ECLASS 8.0                    | 27189234   |

# Approvals

---

|           |                            |
|-----------|----------------------------|
| Approvals | DNV-GL<br>UL + C-UL - FTTA |
|-----------|----------------------------|