


**Rittal – The System.**

Faster – better – everywhere.

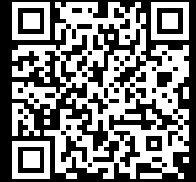

**SZ 2562.500**

**Plastic cable gland plates**

State: 5.4.2026 (Source: [rittal.com/si-sl](https://www.rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2562.500 - Plastic cable gland plates with membranes

Simply pierce the plastic and pull through the cable, protection category IP 65 with careful cable entry.

## Features

Model No.	SZ 2562.500
Product description	Simply pierce the plastic with a sharp object, and pull through the cable.
Material	Plastic to UL 94-V0 Halogen free
Colour	Similar to RAL 7035
Note	The allocation of gland plate sizes is indicated on the relevant enclosures
Dimensions	Width: 339 mm Depth: 149 mm
To fit	Enclosure type: AE
Gland plate	Size: 4
Protection category to IEC 60 529	IP 65
No. of cable entries and Ø (mm) min.-max.	24 x 7-12 48 x 10-15 4 x 15-21 8 x 15-25 4 x 26-35
Packs of	1 pc(s).
Net weight	0,55 kg
Gross weight	0,58 kg
Customs tariff number	39269097
ETIM 9	EC000211
ETIM 8	EC000211

# Features

---

ECLASS 8.0

27142421

---

Product description

SZ Plastic cable gland plate, with membranes, WD: 339x149 mm,  
size: 4