

# Rittal – The System.

Faster – better – everywhere.



## SV 3073.000

## Nosilec zbiralnih sponk

State: 21.5.2026 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SV 3073.000 - Nosilec zbiralnih sponk

Za sisteme zbiralnih sponk 1250 A (100 mm), 1600 A (185 mm), 2500 A (150 mm), 3000 A (150 mm).

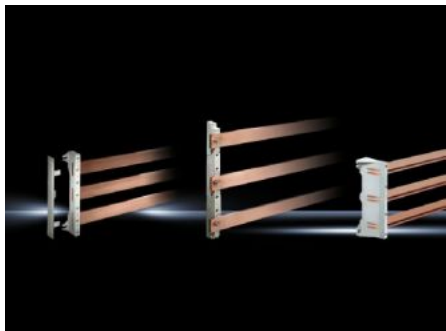

## Features

Št. Modela	SV 3073.000
Material	Termoplastični poliester (PBT), ojačan s steklenimi vlakni Protipožarna zaščita v skladu z UL 94-V0
Barva	RAL 7035
Število polov	3-pole 100 mm
Za namestitev zbiralnih sponk	30 x 10 40 x 10 50 x 10 60 x 10
Maks. nazivni tok	1.250 A
Mere	Širina: 22 mm Višina: 320 mm Globina: 70 mm
Paketi	4 pc(s).
Neto teža	1,612 kg
Bruto teža	1,83 kg
Carinska tarifna številka	85469010
ETIM 9	EC001166

# Features

---

ETIM 8	EC001166
ECLASS 8.0	27400607
Opis izdelka	SV Busbar support, 3-pole, 100 mm bar centre distance, for busbar WH: 30-60x10 mm

# Approvals

---

Explanations	Declaration of conformity Declaration of conformity UK
--------------	---