


**Rittal – The System.**

Faster – better – everywhere.

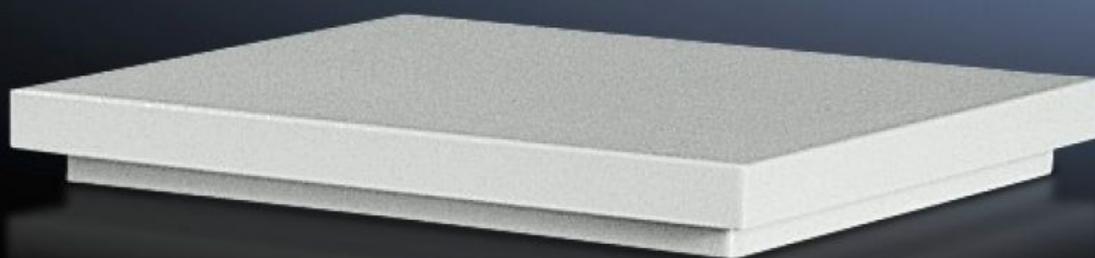

**SK 3148.007**

**Strešni ventilator, strešno  
prezračevanje**

State: 31.5.2026 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SK 3148.007 - Strešni ventilator, strešno prezračevanje

May be installed in any sufficiently large roof surface, air throughput 360 m<sup>3</sup>/h.

## Features

Št. Modela	SK 3148.007
Zasnova	brez motorja ventilatorja
Product modification	Montažni izrezi niso združljivi. Če ponovno uporabite strešno ploščo, je potreben adapterski okvir 5050.700.
Material	Jeklena pločevina, lakirano
Barva	RAL 7035
Obseg dobave	Tesnilni in montažni deli Šablona za vrtanje
Mere	Širina: 420 mm Višina: 65 mm Globina: 340 mm
Izrez za montažo	Širina izreza: 345 mm Globina izreza: 265 mm
IP razred zaščite po IEC 60 529	IP 43
Opomba	Z dodatno namestitvijo držala filtra s filtrirno podlogo in s strešnim prezračevalnim sistemom 3148.007 lahko dosežete razred zaščite IP 44
Delovno temperaturno območje	-10 °C...60 °C
Paketi	1 pc(s).
Neto teža	2,644 kg
Bruto teža	2,844 kg
Carinska tarifna številka	73269098
ECLASS 8.0	27180716
Opis izdelka	SK Roof vent, without fan motor, WHD: 420x65x340 mm