


Rittal – The System.

Faster – better – everywhere.

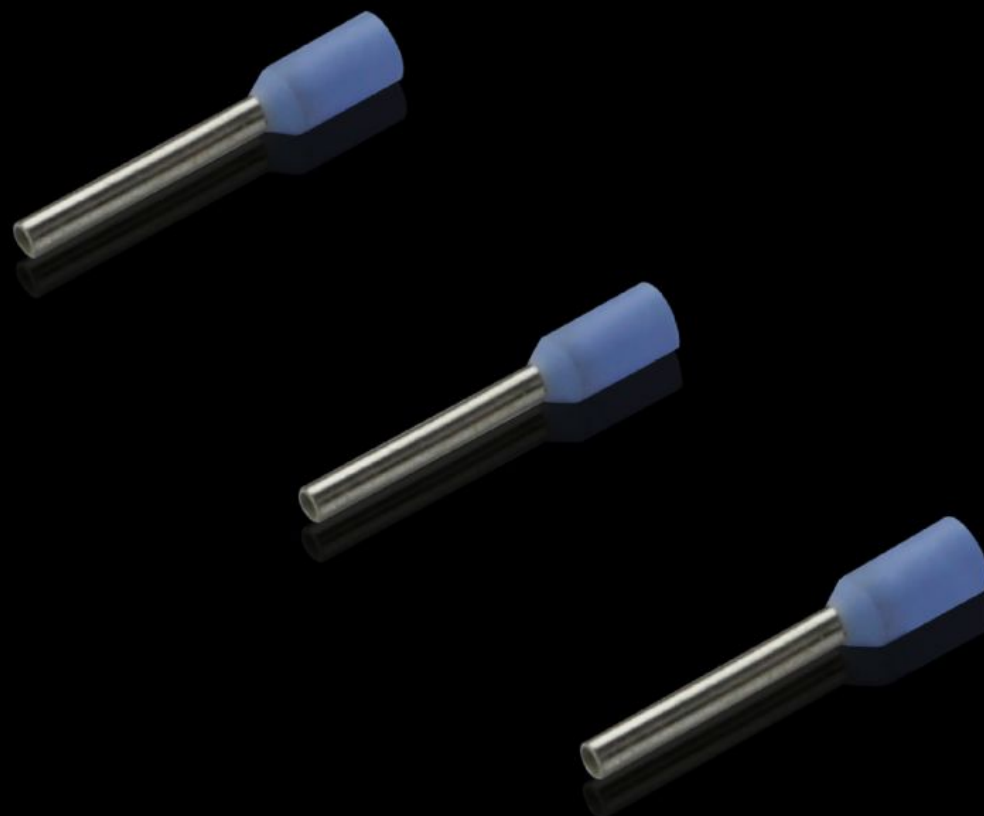

AS 4050.754 Končni tulci za žice

State: 18.6.2026 (Source: rittal.com/si-sl)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4050.754 - Končni tulci za žice ohlapno

S plastično objemko.

Features

Št. Modela	AS 4050.754
Opis izdelka	S plastičnimi tulci.
Tehnični podatki	Toplotno odporno do 105 °C
Material	E-Cu, galvanizirano Plastični obroč: polipropilen
Barva	Svetlo modra
Dolžina	8 mm
AWG	24
Notranji premer	1,8 mm
Rittal barvna koda	Yes
Za prečni prerez	0,25 mm ²
Opomba	UL certificirano v povezavi z ustreznim orodjem, kot so stroji za stiskanje. Za individualno svetovanje se obrnite na svojega prodajnega svetovalca pri podjetju Rittal.
Standardi	AEH DIN 46228
Obrazec za dostavo	Loose
Paketi	500 pc(s).
Neto teža	0,5 kg
Bruto teža	0,026 kg
Carinska tarifna številka	85369010
ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290

Features

Opis izdelka

Wire end ferrules for manual preassembly, 0.25 mm², AWG 24, 8 mm, light blue, loosely packed, 500 pc(s).

Approvals

Approvals

UL + C-UL (listed)
UR