


Rittal – The System.

Faster – better – everywhere.

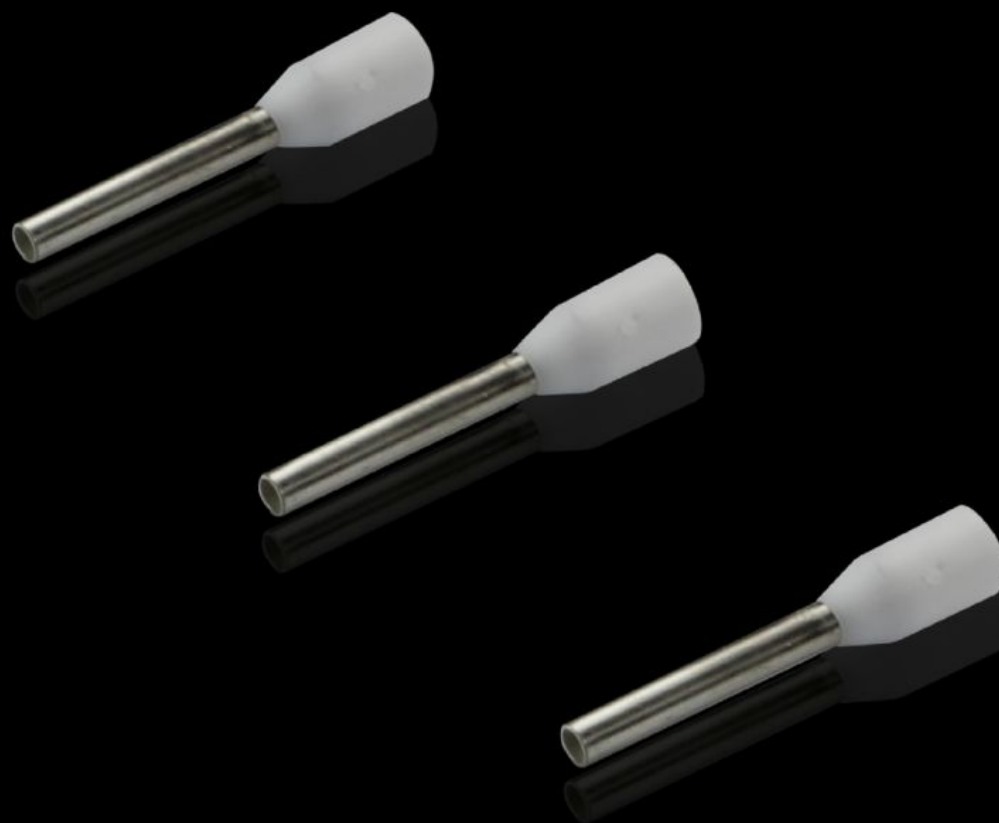

AS 4050.766

Končni tulci za žice

State: 11.5.2026 (Source: rittal.com/si-sl)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4050.766 - Končni tulci za žice ohlapno

S plastično objemko.

Features

Št. Modela	AS 4050.766
Opis izdelka	S plastičnimi tulci.
Tehnični podatki	Toplotno odporno do 105 °C
Material	E-Cu, galvanizirano Plastični obroč: polipropilen
Barva	Bela
Dolžina	10 mm
AWG	18
Notranji premer	2,8 mm
Rittal barvna koda	Yes
Za prečni prerez	0,75 mm ²
Opomba	UL certificirano v povezavi z ustreznim orodjem, kot so stroji za stiskanje. Za individualno svetovanje se obrnite na svojega prodajnega svetovalca pri podjetju Rittal.
Standardi	AEH DIN 46228
Za model št.	4051.205 4051.210 4050.452
Obrazec za dostavo	Loose
Paketi	500 pc(s).
Neto teža	0,5 kg
Bruto teža	0,049 kg
Carinska tarifna številka	85369010

Features

ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290
Opis izdelka	Wire end ferrules for wire processing, 0.75 mm ² , AWG 18, 10 mm, white, loose, 500 pcs.

Approvals

Approvals	UL + C-UL (listed) UR
-----------	--------------------------