


# Rittal – The System.

Faster – better – everywhere.

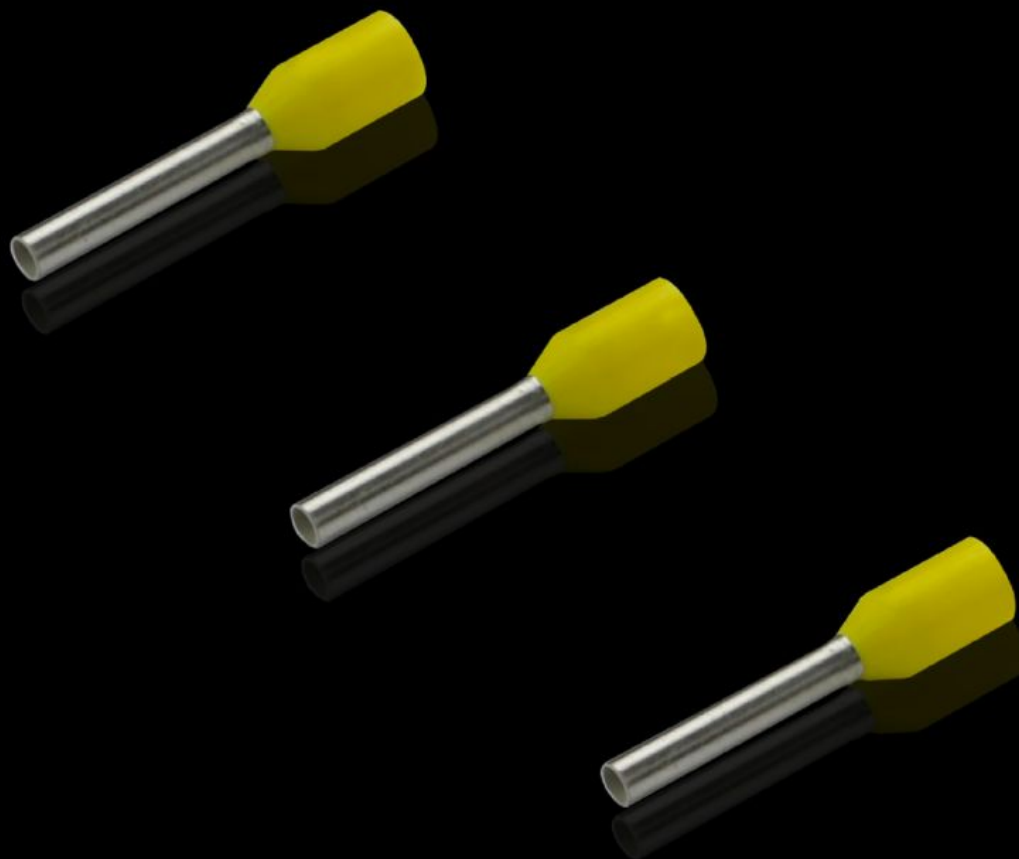

## AS 4050.770 Končni tulci za žice

State: 8.7.2026 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.770 - Končni tulci za žice ohlapno

S plastično objemko.

## Features

|                           |   |
|---------------------------|---|
| Št. Modela                | AS 4050.770   |
| Opis izdelka              | S plastičnimi tulci.  |
| Tehnični podatki          | Toplotno odporno do 105 °C  |
| Material                  | E-Cu, galvanizirano<br>Plastični obroč: polipropilen  |
| Barva                     | Rumena  |
| Dolžina                   | 10 mm   |
| AWG                       | 18  |
| Notranji premer           | 3 mm  |
| Rittal barvna koda        | Yes   |
| Za prečni prerez          | 1 mm <sup>2</sup>   |
| Opomba                    | UL certificirano v povezavi z ustreznim orodjem, kot so stroji za stiskanje.<br>Za individualno svetovanje se obrnite na svojega prodajnega svetovalca pri podjetju Rittal. |
| Standardi                 | AEH DIN 46228   |
| Za model št.              | 4051.205<br>4051.210  |
| Obrazec za dostavo        | Loose   |
| Paketi                    | 500 pc(s).  |
| Neto teža                 | 0,5 kg  |
| Bruto teža                | 0,058 kg  |
| Carinska tarifna številka | 85369010  |
| ETIM 9                    | EC000005  |

## Features

---

|              |   |
|--------------|---|
| ETIM 8       | EC000005  |
| ECLASS 8.0   | 36659290  |
| Opis izdelka | Wire end ferrules for wire processing, 1 mm <sup>2</sup> , AWG 18, 10 mm, yellow, loose, 500 pcs. |

---

## Approvals

---

|           |                          |
|-----------|--------------------------|
| Approvals | UL + C-UL (listed)<br>UR |
|-----------|--------------------------|

---