


# Rittal – The System.

Faster – better – everywhere.

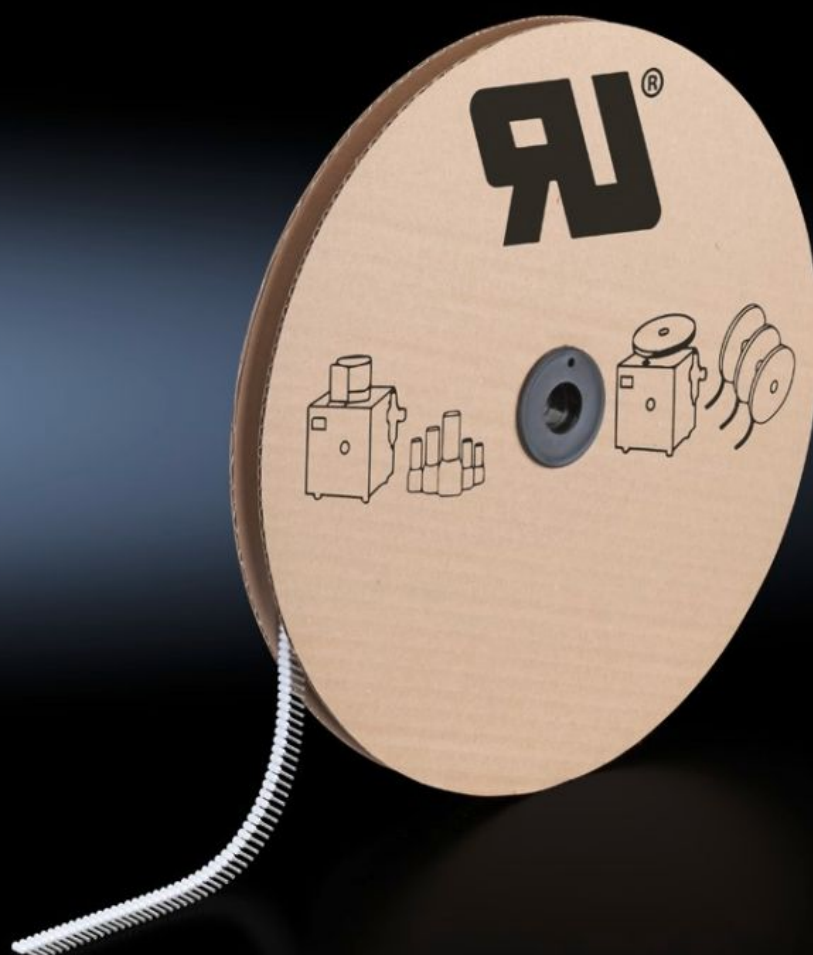

## AS 4051.599 Končni tulci za žice

State: 11.5.2026 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4051.599 - Končni tulci za žice na kolutu

S plastično objemko.

## Features

Št. Modela	AS 4051.599
Tehnični podatki	Toplotno odporno do 105 °C
Material	E-Cu, galvanizirano Plastični obroč: polipropilen
Barva	Bela
Dolžina	8 mm
AWG	18
Notranji premer	2,8 mm
Rittal barvna koda	Yes
Za prečni prerez	0,75 mm <sup>2</sup>
Opomba	UL certificirano v povezavi z ustreznim orodjem, kot so stroji za stiskanje.
Standardi	AEH DIN 46228
Obrazec za dostavo	Taped
Paketi	5.000 pc(s).
Neto teža	5 kg
Bruto teža	0,598 kg
Carinska tarifna številka	85369010
ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290
Opis izdelka	Wire end ferrules for crimping machines, 0.75 mm <sup>2</sup> , AWG 18, 8 mm, orange, on belt, 5000 pc(s).

# Approvals

---

Approvals

UL + C-UL (listed)

UR