
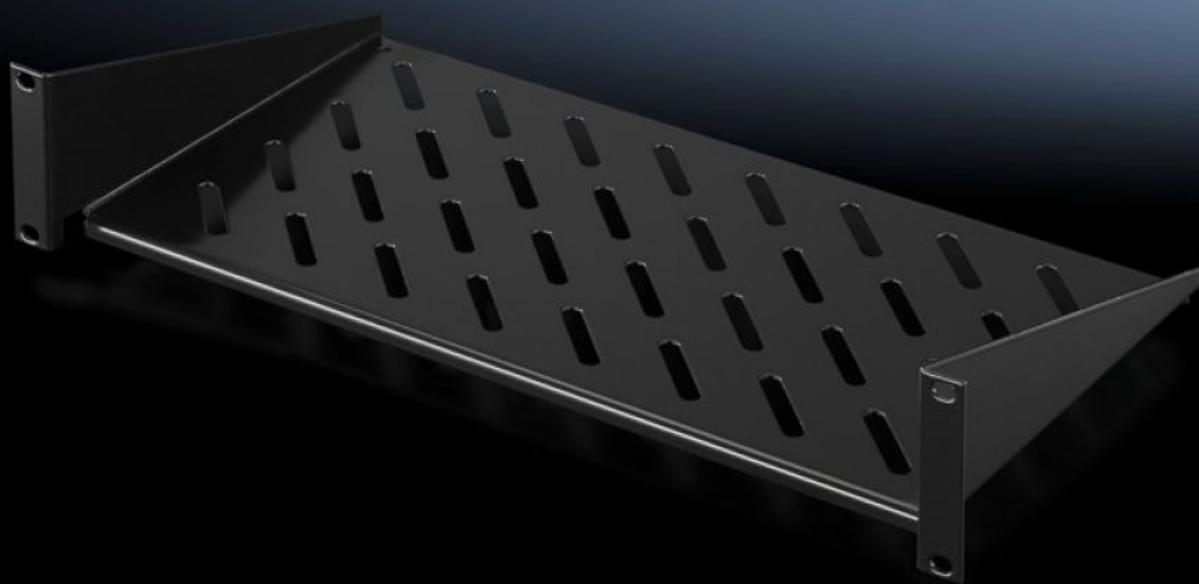


Rittal – The System.

Faster – better – everywhere.

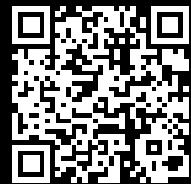

DK 5501.625

**Component shelf 2 U, static
installation**

State: 1.2.2026 (Source: ittal.com/si-si)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL



IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

DK 5501.625 - Component shelf 2 U, static installation

Component shelf 2 U, static installation for attachment to the 482.6 mm (19") system punchings.
Load capacity: 25 kg.

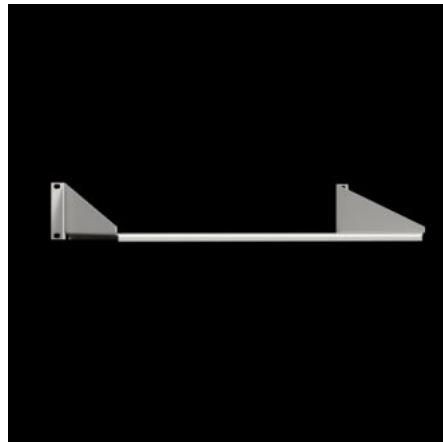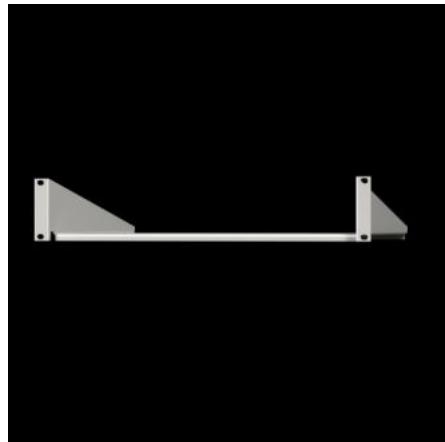

Features

Model No.	DK 5501.625
Design	482.6 mm (19")
Product description	For mounting between 482.6 mm (19") mounting angles.
Material	Sheet steel
Surface finish	Spray-finished
Colour	RAL 9005
Load capacity	25 kg surface load, static
Note	Not suitable for combination with telescopic slides.
Dimensions	Width: 482.6 mm Depth: 400 mm
Packs of	1 pc(s).
Net weight	3.297
Gross weight	3.52
PCF per pack (cradle-to-gate)	11.4 kg CO ₂ eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared

Features

Customs tariff number 73269098

EAN 4028177679061

E-Number Sweden E7239586

ETIM 9 EC002620

ECLASS 8.0 27189261