

Rittal – The System.

Faster – better – everywhere.



DK 5502.101 Kabelski kanal

State: 23.5.2026 (Source: rittal.com/si-sl)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 5502.101 - Kabelski kanal za TS IT

Cable duct with removable duct cover hinged on both sides.

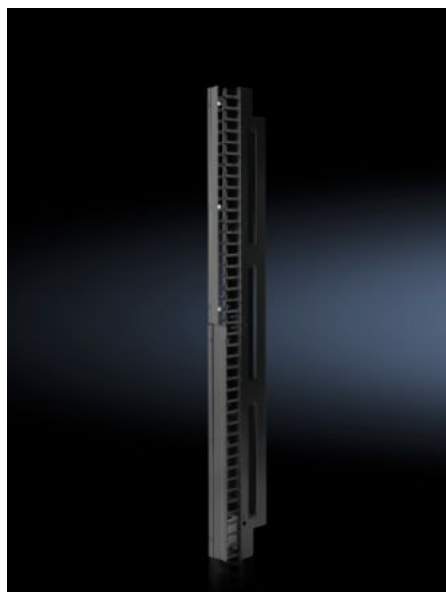

Features

Št. Modela	DK 5502.101
Prednosti	<p>Enostavna montaža s hitrim pritrditvijo brez orodja</p> <p>Visoka gostota zaradi napeljave kablov v obliki črke U</p> <p>Primerno za povezovanje hrbet ob hrbtu</p> <p>Kabelski kanal se lahko uporablja kot zaščitni element za preprečevanje kratkih stikov zraka znotraj hladnega hodnika</p> <p>Zaklepne kabselske uvodnice se lahko z montažnimi deli namestijo na standardne montaže 1 U</p>
Material	<p>Jeklena pločevina</p> <p>Plastika po UL 94-HB</p>
Barva	RAL 9005
Obseg dobave	<p>Pokrov in montažni deli</p> <p> vključno s 4 držali za nadomestne kable</p>
Možnosti namestitve	<p>V TS IT z montažnimi kotniki 482,6 mm (19"), višina 2200 mm</p> <p>V TS IT z montažnim okvirjem 482,6 mm (19"), višina 2000 mm</p> <p>V Data Rack s 45 U</p>
Enote	42 U

Features

Mere	Širina: 95 mm Višina: 1.866 mm Globina: 150 mm
Paketi	1 pc(s).
Neto teža	8,46 kg
Bruto teža	8,86 kg
Carinska tarifna številka	73269098
ETIM 9	EC000012
ECLASS 8.0	27400703
Opis izdelka	DK Cable duct, 42 U, for TS IT, Height 2000 mm: with mountingframe, Height 2200 mm: with profiles