


**Rittal – The System.**

Faster – better – everywhere.

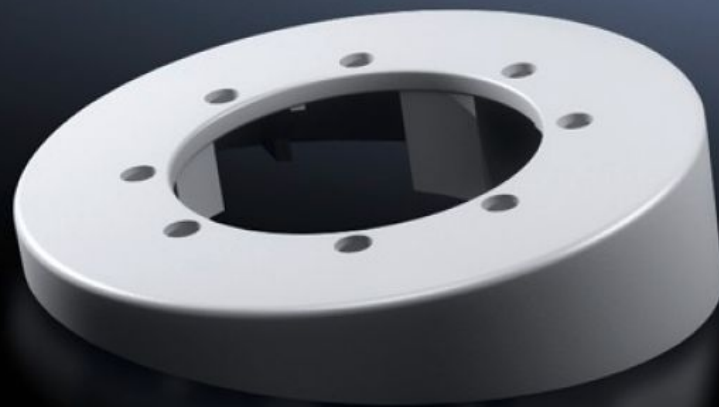

# CP 6206.400

## Nagibni adapter 10°

State: 8.7.2026 (Source: [rittal.com/si-sl](https://www.rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# CP 6206.400 - Nagibni adapter 10° za priključek nosilne roke Ø 130 mm

Za namestitev med sklopko sistema 60/120 ali priključek, sistem 60/120 ali kotno sklopko, sistem 60/120 in nadzorno ploščo.

## Features

Št. Modela	CP 6206.400
Zasnova	Za montažo med nadzorno ploščo in Sponka CP 60/120/180 za priključek nosilne roke Ø 130 mm, 6206.300, 6212.300, 6218.300 Priključek CP 60/120 za priključek nosilne roke Ø 130 mm, 6206.320, 6212.320 Kotna sponka 90°, sistem 60/120 za priključek nosilne roke Ø 130 mm, CP 6206.380, 6212.380
Opis izdelka	Za montažo med sklopnim sistemom 60/120 ali pritrdilnim sistemom 60/120 ali kotnim sklopnim sistemom 60/120 in nadzorno ploščo.
Material	Tlačno liti cink
Barva	RAL 7035
Obseg dobave	Tesnila Sestavni deli
Rifid y/n	Yes
Paketi	1 pc(s).
Neto teža	0,6 kg
Bruto teža	0,617 kg
Carinska tarifna številka	79070000
ETIM 9	EC000882
ECLASS 8.0	27400556
Opis izdelka	CP Tilting adaptor 10°, CP 60/120, for support arm connection Ø 130 mm

# Approvals

---

Explanations

Manufacturer's declaration