

**Rittal – The System.**

Faster – better – everywhere.



**DK 7000.620**

**Polica za komponente, statična  
namestitvev**

State: 5.6.2026 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7000.620 - Polica za komponente, statična namestitvev za TE

Are attached directly to the front and rear 482.6 mm (19") mounting angles, load capacity: 30 kg.

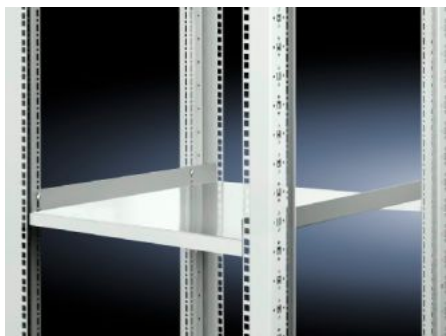

## Features

Št. Modela	DK 7000.620
Material	Jeklena pločevina
Površinska obdelava	lakirano
Barva	RAL 7035
Obseg dobave	Sestavni deli
Distance between mounting levels	495 mm
Load capacity static	300 N
Opomba	Ni primerno za kombinacijo s teleskopskimi drsniki.
Kontaktna površina	Širina: 505 mm Globina: 410 mm
Mere	Širina: 511 mm Višina: 22 mm Globina: 413 mm
Paketi	1 pc(s).
Neto teža	3,25 kg
Bruto teža	3,7 kg
Carinska tarifna številka	94039910

# Features

---

ETIM 9	EC002620
ECLASS 8.0	27189261
Opis izdelka	TE Component shelf, WHD: 511x22x413 mm, 30 kg, static, distance between levels: 495 mm, static installation, For TE, RAL 7035

---