 


# Rittal – The System.

Faster – better – everywhere.



## DK 7827.550

## TS installation kit, width-variable

State: 31.7.2025 (Source: [rittal.com/si-sl](https://www.rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7827.550 - TS installation kit, width-variable 482.6 mm (19")/metric in TS

Universal depth stays to which both L-shaped and cranked mounting angles may be variably mounted in the depth and width.

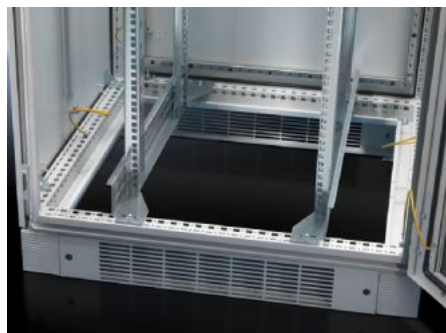

## Features

Model No.	DK 7827.550
Product description	Universal depth stays to which both L-shaped and cranked mounting angles may be variably mounted in the depth and width. Installation kit for all width dimensions: Imperial mounting dimensions 19"/21"/23"/24", metric dimensions 18/20 SU
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
To fit	Enclosure type: TS 8 Depth: 800 mm
Load capacity	200 kg static load per level
Packs of	1 set(s)
Net weight	2.025
Gross weight	2.125
Customs tariff number	73182900
EAN	4028177616035
ECLASS 8.0	27189234

# Tender text

TS divider kit, width-variable, 482.6 mm (19")/metric

For cranked and L-shaped mounting angles for all width dimensions:

imperial: 482.6 mm (19 inch) / 533.4 mm (22 inch) / 584.2 mm (23 inch) / 609.6 mm (24 inch),

metric: 485 mm (18 SU) / 535 mm (20 SU)

Dimension: D 800 mm

Material: Sheet steel, zinc-plated, passivated

Make/model: Rittal

Type: DK-TS depth stay DK 7827550 or equivalent