


# Rittal – The System.

Faster – better – everywhere.

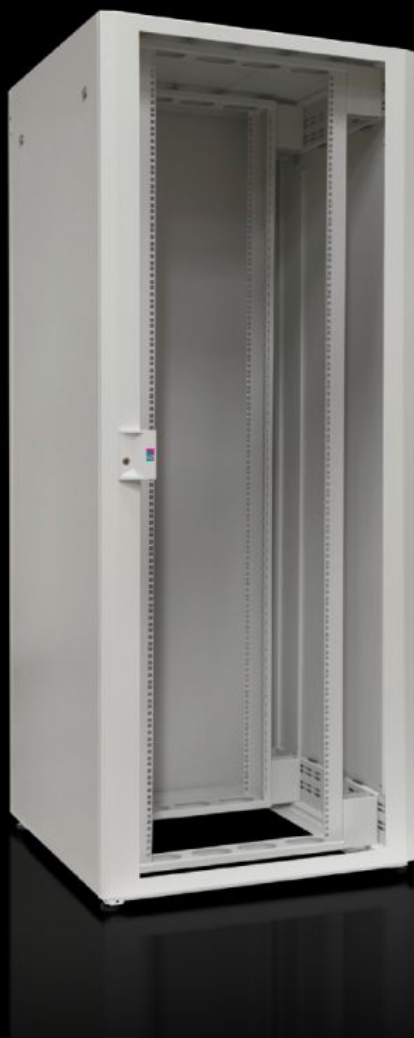

## TE 7888.530

## Omrežni nosilec TE 8000

State: 22.7.2026 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TE 7888.530 - Omrežni nosilec TE 8000

TE 8000 IT enclosure with glazed door, prepared for individual interior installation.

## Features

|                     |                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                      |
|---------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Št. Modela          | TE 7888.530                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                          |
| Zasnova             | s stranskimi ploščami                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                |
| Prednosti           | Brez okvirja<br>Optimalna dostopnost<br>Enostavno razstavljanje in tudi enostavna namestitvev<br>Zamenljiv tečaj vrat                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                |
| Material            | Jeklena pločevina<br>Steklena vrata: enoslojno varnostno steklo, 3 mm                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                |
| Površinska obdelava | Montažni okvir: Temeljni premaz<br>Plošče ohišja: prašno barvano                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                     |
| General colour      | RAL 7035                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                             |
| Barva               | RAL 7035                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                             |
| Obseg dobave        | Samostoječi 482,6 mm (19") montažni okvirji, spredaj in zadaj, z nastavljivo globino<br>Steklena sprednja vrata, vključno s 130° tečajem, okrasnim ročajem in varnostno ključavnico 3524 E<br>Vrata iz jeklene pločevine na zadnji strani, vključno s 130° tečajem, varnostna ključavnica 3524 E<br>Osnovni okvir z največjim izrezom (za opsijsko postavitvev z modularnimi ploščami)<br>Strešna plošča s skritim izrezom za vhod kablov in opsijskim ventilatorjem<br>4 nivelirne noge, M10 (priložene)<br>4 distančniki, 20 mm (priloženi) za dvig strešne plošče<br>Stranske plošče, možnost zaklepanja, vključno z varnostno ključavnico 3524 E |
| Mere                | Širina: 800 mm<br>Višina: 2.000 mm<br>Globina: 800 mm                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                |

## Features

|                                                                 |                                                                            |
|-----------------------------------------------------------------|----------------------------------------------------------------------------|
| Enote                                                           | 42 U                                                                       |
| Enote                                                           | 42 U                                                                       |
| Prosti montažni prostor do višine 482,6 mm (19"), spredaj/zadaj | 130 mm / 130 mm /                                                          |
| Razdalja med nivoji (kot je dobavljeno)                         | 495 mm                                                                     |
| Nosilnost                                                       | 4.000 N                                                                    |
| Razred zaščite po IEC 60 529                                    | IP 20                                                                      |
| Osnovni material                                                | Sheet steel                                                                |
| Paketi                                                          | 1 pc(s).                                                                   |
| Neto teža                                                       | 104 kg                                                                     |
| Bruto teža                                                      | 106 kg                                                                     |
| Carinska tarifna številka                                       | 94032080                                                                   |
| ETIM 9                                                          | EC002499                                                                   |
| ECLASS 8.0                                                      | 27180207                                                                   |
| Opis izdelka                                                    | TE Network enclosure TE 8000, WHD: 800x2000x800 mm, 42 U, With glazed door |

## Approvals

|              |                           |
|--------------|---------------------------|
| Explanations | Declaration of conformity |
|--------------|---------------------------|