


# Rittal – The System.

Faster – better – everywhere.

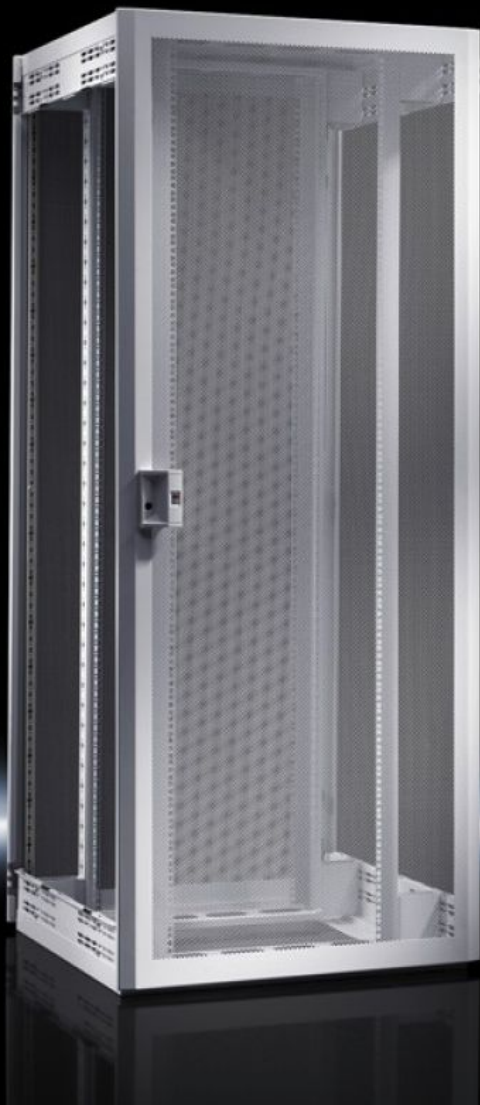

## TE 7888.892

## Omrežni nosilec TE 8000

State: 5.6.2026 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TE 7888.892 - Omrežni nosilec TE 8000 Prezračevano

IT enclosure system, suitable for dismantling, with depth-variable 482.6 mm (19") mounting frame.

## Features

Št. Modela	TE 7888.892
Prednosti	Brez okvirja Optimalna dostopnost Enostavno razstavljanje in tudi enostavna namestitvev Zamenljiv tečaj vrat
Material	Jeklena pločevina
Površinska obdelava	Montažni okvir: Temeljni premaz Plošče ohišja: prašno barvano
General colour	RAL 7035
Barva	RAL 7035
Obseg dobave	Samostoječi 482,6 mm (19") montažni okvirji, spredaj in zadaj, z nastavljivo globino Prezračevana vrata iz jeklene pločevine (površina prezračevanja > 67 %), sprednja, z okrasnim ročajem, 130° tečaj, varnostna ključavnica 3524 E Prezračevana vrata iz jeklene pločevine (prezračevana površina > 67 %), zadnja s 130° tečajem, varnostna ključavnica 3524 E Osnovni okvir z največjim izrezom (za opsijsko postavitvev z modularnimi ploščami) Strešna plošča s skritim izrezom za vhod kablov in opsijskim ventilatorjem 4 nivelirne noge, M10 (priložene) 4 distančniki, 20 mm (priloženi) za dvig strešne plošče Komplet za povezovanje
Mere	Širina: 800 mm Višina: 2.000 mm Globina: 1.000 mm
Enote	42 U

# Features

Enote	42 U
Prosti montažni prostor do višine 482,6 mm (19"), spredaj/zadaj	80 mm / 130 mm
Razdalja med nivoji (kot je dobavljeno)	745 mm
Nosilnost	7.000 N
Razred zaščite po IEC 60 529	IP 20
Osnovni material	Sheet steel
Paketi	1 pc(s).
Neto teža	78 kg
Bruto teža	81 kg
Carinska tarifna številka	94032080
ETIM 9	EC002499
ECLASS 8.0	27180207
Opis izdelka	TE Network enclosure TE 8000, WHD: 800x2000x1000 mm, 42 U, vented, without side panels

# Approvals

Explanations	Declaration of conformity
--------------	---------------------------