

Rittal – The System.

Faster – better – everywhere.



VX 8100.733

**Luknjani profil z montažno
prirobnico, 23 x 89 mm, nerjavno
jeklo**

State: 21.5.2026 (Source: rittal.com/si-sl)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE



SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



VX 8100.733 - Luknjani profil z montažno prirobnico, 23 x 89 mm, nerjavno jeklo za VX, VX SE

Za prilagodljivo, individualno notranjo namestitev okvirja na notranji montažni ravni.

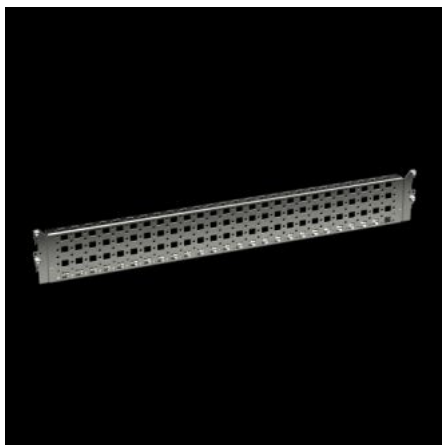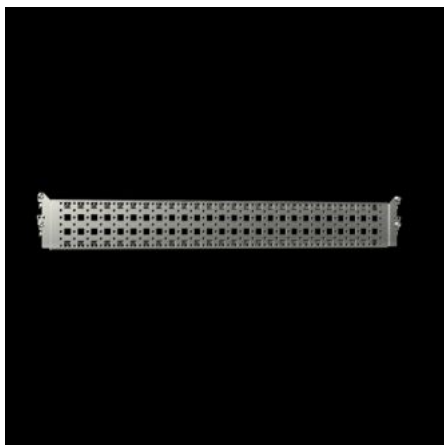

Features

Št. Modela	VX 8100.733
Opis izdelka	Za spremenljivo in individualno notranje oblikovanje okvirja ohišja na notranji montažni ravnini.
Prednosti	Preprosto namestite v sistemske luknje in jih privijte Sistemske luknje na vseh štirih straneh Z režami na vrhu in dnu za matice, za pritrditev lastnih komponent z metričnimi vijaki
Material	Nerjavno jeklo 1.4301 (AISI 304)
Obseg dobave	Sestavni deli
Možnosti namestitve	V VX na notranji montažni ravni, na delu ohišja VX V VX SE, na delu ohišja skupaj z adaptersko tirnico VX Na enakih luknjanih profilih z montažnimi prirobnicami
Primerno za	Vrsta ohišja: VX VX SE Širina/globina: 800 mm
Paketi	2 pc(s).
Neto teža	1,788 kg

Features

Bruto teža	2,02 kg
PCF na paket (od zibelke do vrat)	63,92
Carinska tarifna številka	73269098
ETIM 9	EC002620
ECLASS 8.0	27189234
Opis izdelka	VX Punched section, with mounting flange 23 x 89 mm, for W/D: 800 mm, stainless steel

Approvals

Explanations	PCF-declaration
--------------	-----------------