


**Rittal – The System.**

Faster – better – everywhere.

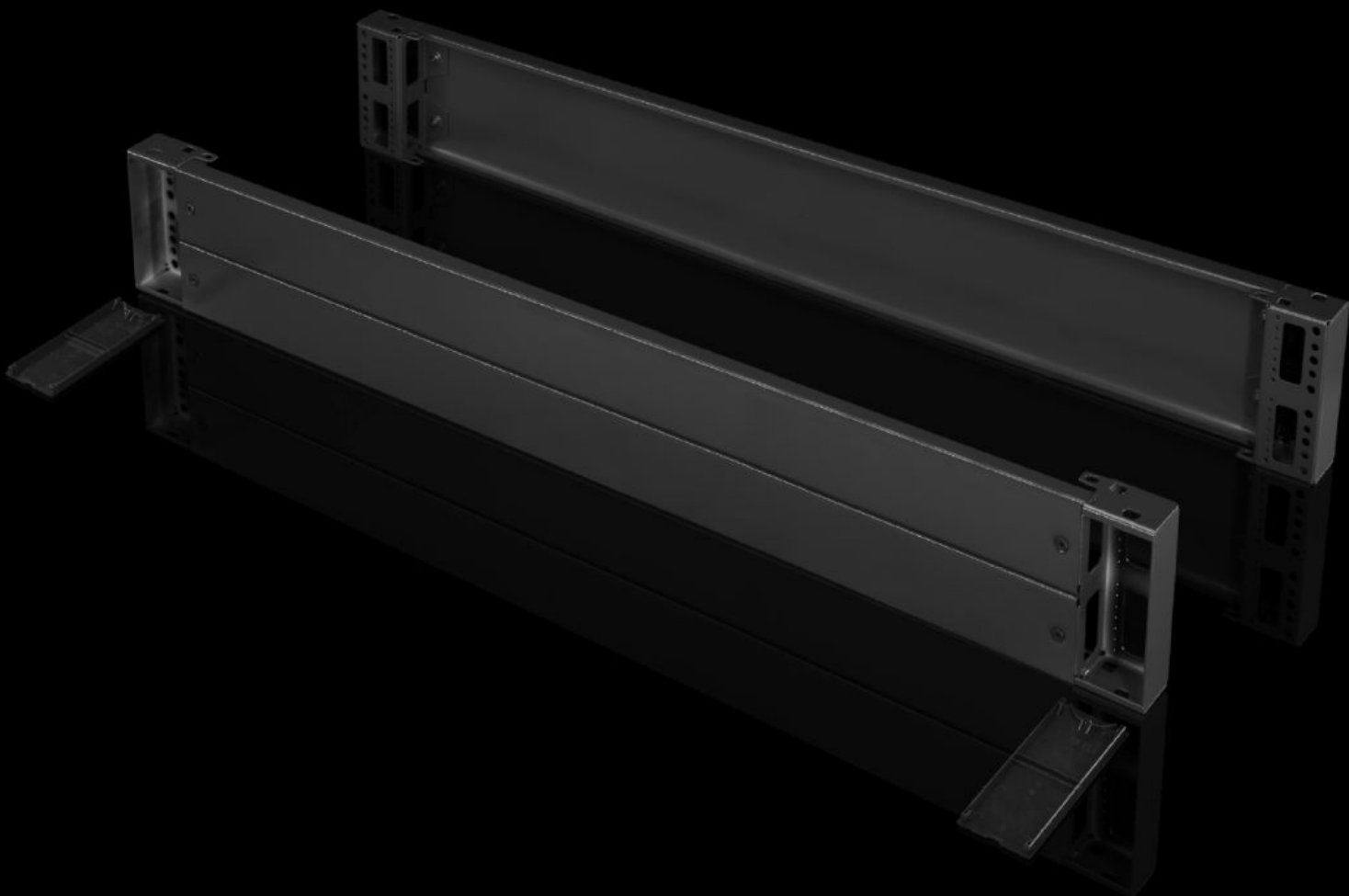

**TS 8602.200**

**Podnožje/komponente podnožja,  
spredaj in zadaj, 200 mm**

State: 22.5.2026 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TS 8602.200 - Podnožje/komponente podnožja, spredaj in zadaj, 200 mm Jeklena pločevina, za TS, TS IT, SE, CM, TP, PC, IW, TE

Base/plinth component consisting of one trim panel and two pre-configured corner pieces. In 200 mm high base/plinth components, one trim panel is divided into two for cable entry.

## Features

Št. Modela	TS 8602.200
Zasnova	zaprto
Material	Komponente podnožja/podstavka: jeklena pločevina Pokrovčki: plastika
Površinska obdelava	lakirano
Barva	RAL 7022 Zaščitni pokrovčki: RAL 9005
Obseg dobave	2 komponenti podnožja/podstavka 4 pokrovčki Sestavni deli
Mere	Višina: 200 mm
Primerno za	Vrsta ohišja: TS: = 1.200 mm Vrsta ohišja: SE Vrsta ohišja: CM Vrsta ohišja: TP Vrsta ohišja: PC Vrsta ohišja: IW Vrsta ohišja: TS IT
Paketi	2 pc(s).
Neto teža	10,52 kg
Bruto teža	11,358 kg
Carinska tarifna številka	94039910
ECLASS 8.0	27182003

# Features

---

Opis izdelka

TS Base/plinth component, front and rear, H: 200 mm, for W: 1200 mm, RAL 7022, sheet steel