

**Rittal – The System.**

Faster – better – everywhere.



**TS 8612.500**

**TS luknjani profil z montažno prirobnico, 23 x 73 mm**

State: 22.5.2026 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TS 8612.500 - TS luknjani profil z montažno prirobnico, 23 x 73 mm

Alternativa luknjanemu profilu TS z montažno prirobnico 17 x 73 mm, z luknjami za matice/ navojne bloke namesto zgornjih in spodnjih utorov. Enostavno namestite in pritrdite.

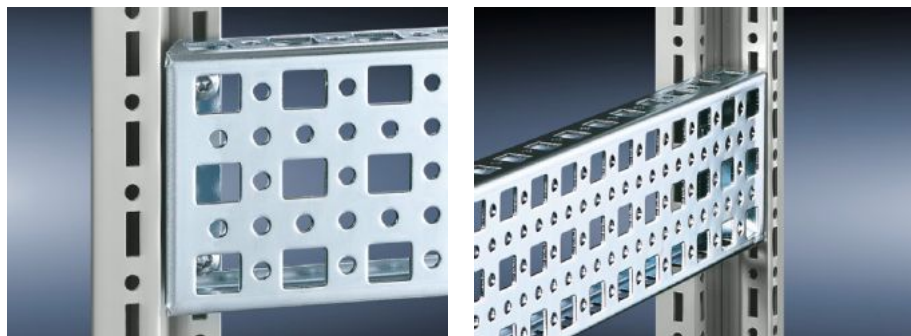

## Features

Št. Modela	TS 8612.500
Opis izdelka	Alternativa ohišju sistema TS 17 x 73 mm, z luknjami za matice/ navojne bloke namesto utorov na zgornjem in spodnjem delu. Enostavno namestite in pritrdite.
Material	Jeklena pločevina
Površinska obdelava	Pocinkano
Obseg dobave	Montažni vijaki
Možnosti namestitve	Na navpičnem delu TS, VX SE ohišja
Primerno za	Vrsta ohišja: the inner mounting level Širina/globina: 1.000 mm
Paketi	4 pc(s).
Neto teža	4,264 kg
Bruto teža	4,463 kg
Carinska tarifna številka	73269098
ETIM 9	EC002625
ECLASS 8.0	27189234

# Features

---

Opis izdelka

TS punched section with mounting flange, 23 x 73 mm, for inner mounting level: W/D: 1000 mm