


Rittal – The System.

Faster – better – everywhere.

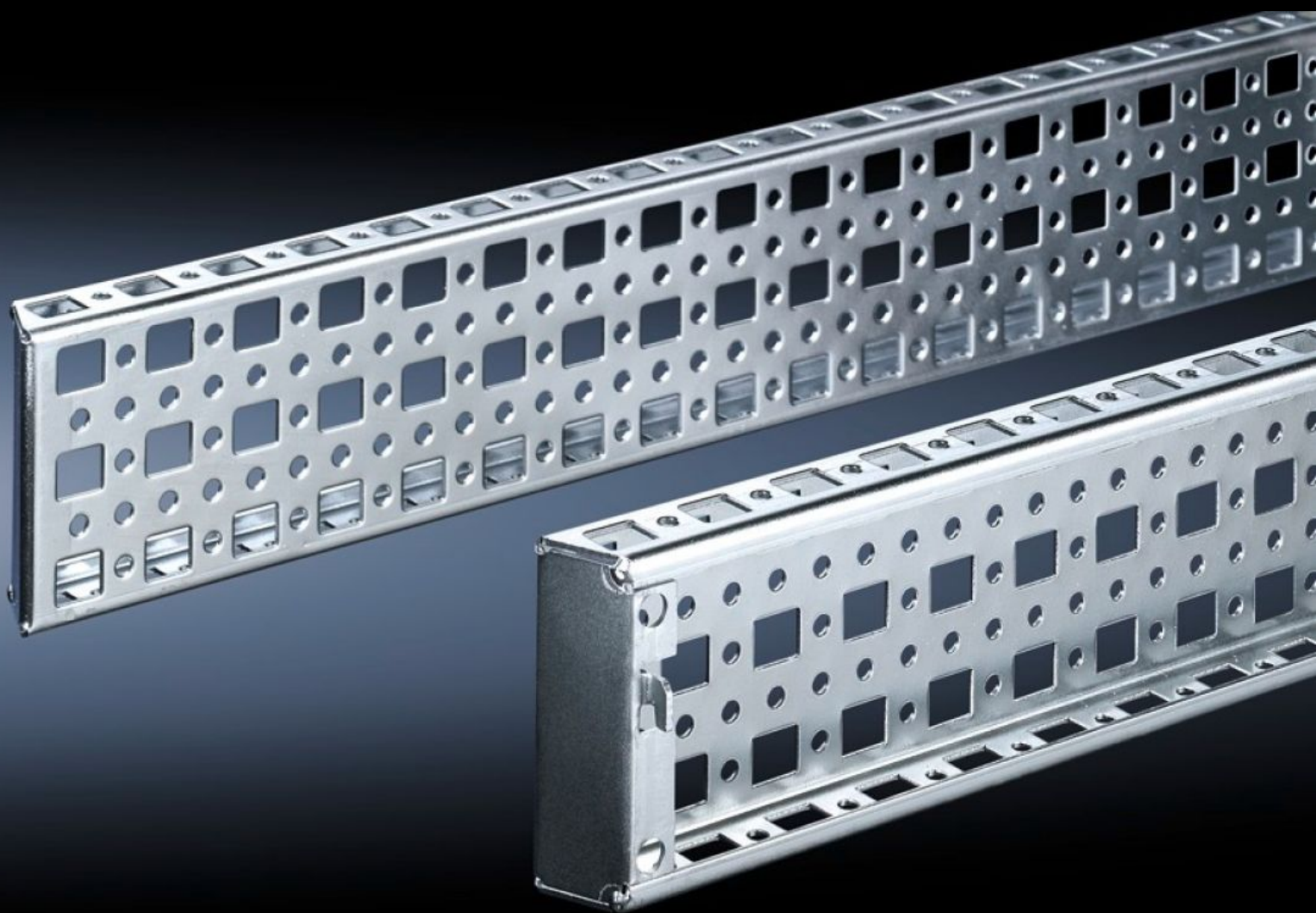

TS 8612.560

TS luknjani profil z montažno prirobnico, 23 x 73 mm

State: 22.5.2026 (Source: rittal.com/si-sl)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



TS 8612.560 - TS luknjani profil z montažno prirobnico, 23 x 73 mm

Alternativa luknjanemu profilu TS z montažno prirobnico 17 x 73 mm, z luknjami za matice/ navojne bloke namesto zgornjih in spodnjih utorov. Enostavno namestite in pritrdite.

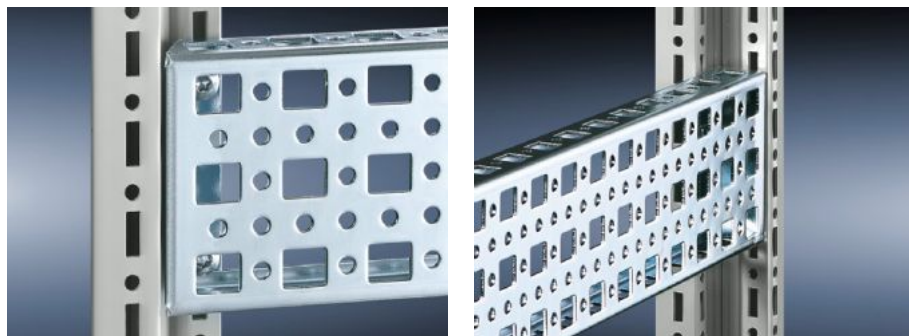

Features

Št. Modela	TS 8612.560
Opis izdelka	Alternativa ohišju sistema TS 17 x 73 mm, z luknjami za matice/ navojne bloke namesto utorov na zgornjem in spodnjem delu. Enostavno namestite in pritrdite.
Material	Jeklena pločevina
Površinska obdelava	Pocinkano
Obseg dobave	Montažni vijaki
Možnosti namestitve	Na navpičnem delu TS, VX SE ohišja
Primerno za	Vrsta ohišja: the inner mounting level Širina/globina: 600 mm
Paketi	4 pc(s).
Neto teža	2,544 kg
Bruto teža	2,74 kg
Carinska tarifna številka	73269098
ETIM 9	EC002625
ECLASS 8.0	27189234

Features

Opis izdelka

TS TS punched section with mounting flange, 23 x 73 mm, for inner mounting level: W/D: 600 mm