


Rittal – The System.

Faster – better – everywhere.

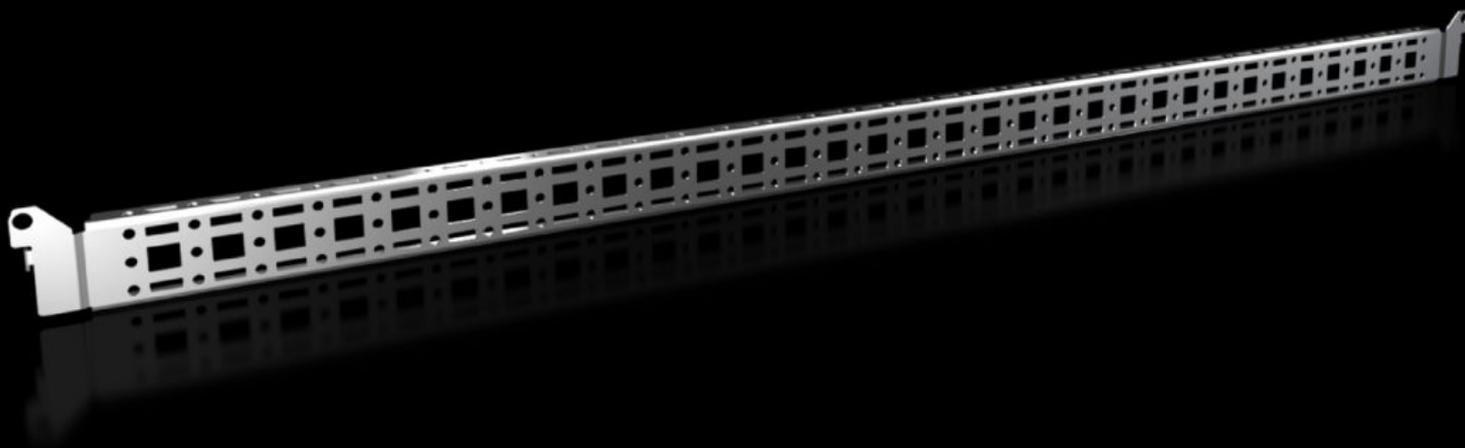

VX 8619.750

Izrezani profil z montažno prirobnico, 14 x 39 mm

State: 11.5.2026 (Source: rittal.com/si-sl)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



VX 8619.750 - Izrezani profil z montažno prirobnico, 14 x 39 mm za VX, VX SE, PC, IW, AX

Za pritrditev kabelskih kanalov, nosilcev kabelskih kanalov, opreme, nameščene na vratih itd.

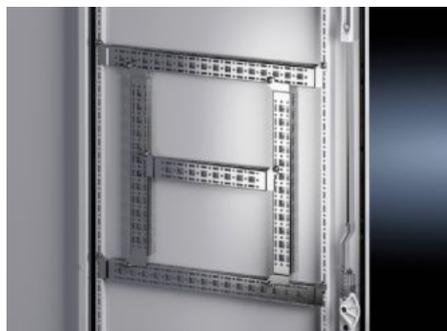

Features

Št. Modela	VX 8619.750
Opis izdelka	Za pritrditev kabelskih kanalov, nosilcev kabelskih cevi, komponent za vrata itd.
Material	Jeklena pločevina
Površinska obdelava	Pocinkano
Obseg dobave	Sestavni deli
Distance between fixing points	875 mm
Za prilagoditev vratih s širino	1.000 mm
Možnosti namestitve VX SE	Širina vrat 900 mm
Možnosti namestitve AX iz nerjavnega jekla	V ohišjih z višino 1000 mm
Navodila za sestavljanje	Za vgradnjo v AX jeklena pločevina, samo v kombinaciji z letvijo za notranjo namestitvev AX
Opomba	Za namestitvev lastnih komponent na luknjani del z montažno prirobnico so potrebni kovinski vijaki ali samorezni vijaki M5

Features

Primerno za	Vrsta ohišja: VX SE AX stainless steel Suitable for width or height or depth: 1.000 mm
Paketi	4 pc(s).
Neto teža	1,776 kg
Bruto teža	2,06 kg
Carinska tarifna številka	73269098
ETIM 9	EC002620
ECLASS 8.0	27189234
Opis izdelka	VX Punched section, with mounting flange 14 x 39 mm, for door width:1000 mm

Approvals

Explanations	PCF-declaration
--------------	-----------------