


# Rittal – The System.

Faster – better – everywhere.

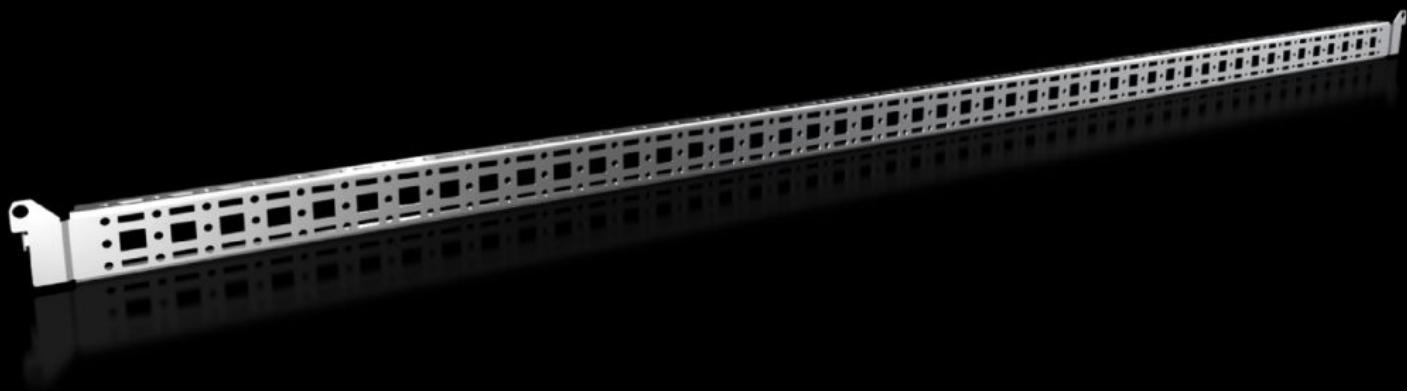

## VX 8619.780

Punched section with mounting  
flange, 14 x 39 mm

State: 28.1.2026 (Source: [rittal.com/si-si](http://rittal.com/si-si))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL



IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

# VX 8619.780 - Punched section with mounting flange, 14 x 39 mm for VX, VX SE, PC, IW, AX

For securing cable ducts, cable conduit holders, equipment installed on the door, etc.

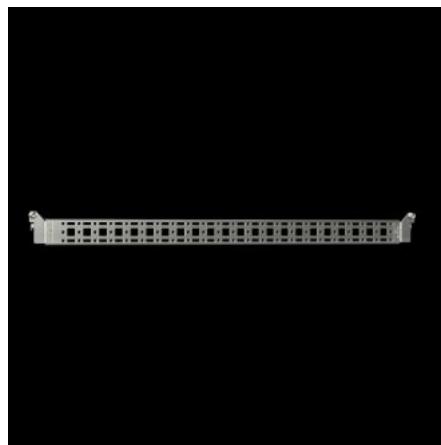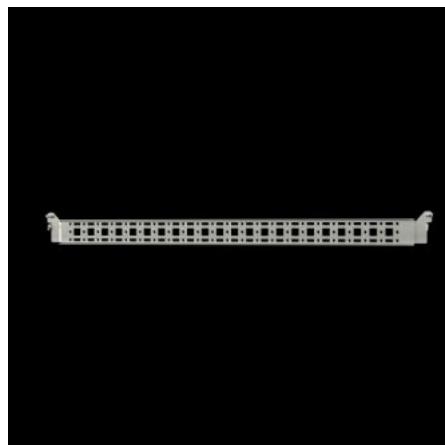

## Features

Model No.	VX 8619.780
Product description	For attaching cable ducts, cable conduit holders, equipment installed on the door, etc.
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
Distance between fixing points	1.275 mm
AX installation options	In enclosure height 1400 mm, in conjunction with rail for interior installation AX
AX stainless steel installation options	In enclosure height 760 mm
Assembly instruction	For installation in AX sheet steel, only in conjunction with rail for interior installation AX
Note	For installing your own components on the punched section with mounting flange, metal screws or self-tapping M5 screws are required

# Features

To fit	Enclosure type: AX Suitable for width or height or depth: 1,400 mm
Packs of	4 pc(s).
Net weight	2.44
Gross weight	2.7
Customs tariff number	73269098
EAN	4028177926844
E-Number Sweden	E3465286
ETIM 9	EC002620
ECLASS 8.0	27189234