


Rittal – The System.

Faster – better – everywhere.

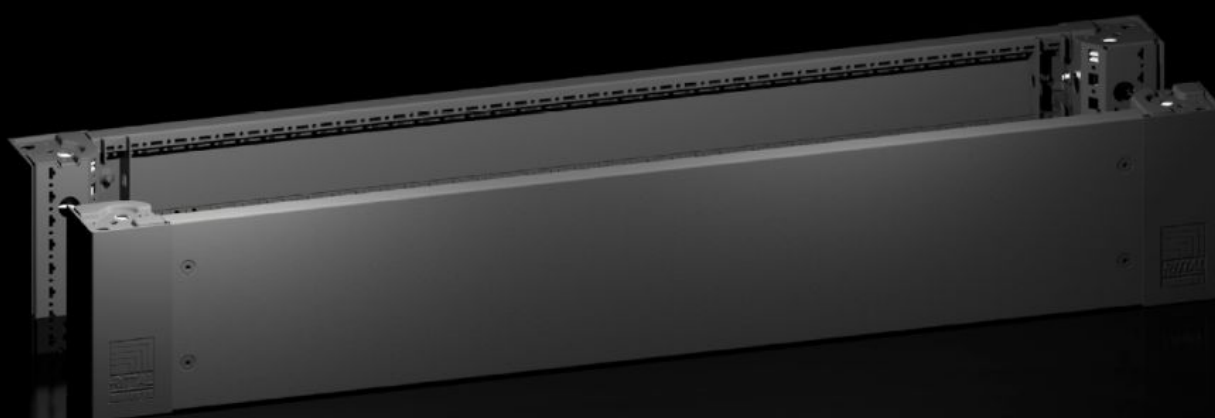

VX 8640.025

**Vogalni element podnožja/
podstavka z obrobami podnožja/
podstavka, spredaj in zadaj, 200
mm**



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES



FRIEDHELM LOH GROUP

VX 8640.025 - Vogalni element podnožja/podstavka z obrobami podnožja/podstavka, spredaj in zadaj, 200 mm za VX, VX IT, VX SE, TE, TS, TS IT, TP, PC, IW

Heavy-duty base/plinth corner pieces with moulded self-positioning to the enclosure, may be used with or without trim panels depending on the application. Large openings in the base/plinth corner piece for optimum access to the screw-fastening point, may be concealed with a plastic corner and baying cover.

Features

| | |
|------------------------|--|
| Št. Modela | VX 8640.025 |
| Material | Podnožje/vogalni kos podnožja: jeklena pločevina Obrobe podnožja/podstavka: jeklena pločevina Kotni in povezovalni pokrov: plastika |
| Barva | RAL 9005 |
| Obseg dobave | 4 vogalni elementi podnožja/podstavka, višina 200 mm 4 vogalni pokrovi 1 povezovalni pokrov 1 obroba podnožja/podstavka, spredaj/zadaj, višina 200 mm 2 obrobi podnožja/podstavka, spredaj/zadaj, višina 100 mm Sestavni deli |
| Opomba | Stranske obrobe podnožja/podstavka zaokrožujejo podnožje/ podstavek ali zagotavljajo dodatno stabilizacijo med podnožjem/ podstavkom oziroma omogočajo notranjo konfiguracijo podnožja/ podstavka |
| Mere | Višina: 200 mm |
| Primerno za | Širina: = 1.200 mm |
| Tipska ocena po UL 50E | Type 1 Type 12 |
| Teža/pakiranje | 12 kg |
| Paketi | 2 pc(s). |
| Neto teža | 11,63 kg |

Features

| | |
|---------------------------|--|
| Bruto teža | 11,63 kg |
| Carinska tarifna številka | 94039910 |
| ETIM 9 | EC000721 |
| ETIM 8 | EC000721 |
| ECLASS 8.0 | 27182003 |
| Opis izdelka | VX Base/plinth corner piece, with base/plinth trim panel, front and rear, H: 200 mm, for W: 1200 mm, sheet steel |

Approvals

| | |
|-----------|------------------|
| Approvals | UL + C-UL - FTTA |
|-----------|------------------|