


**Rittal – The System.**

Faster – better – everywhere.

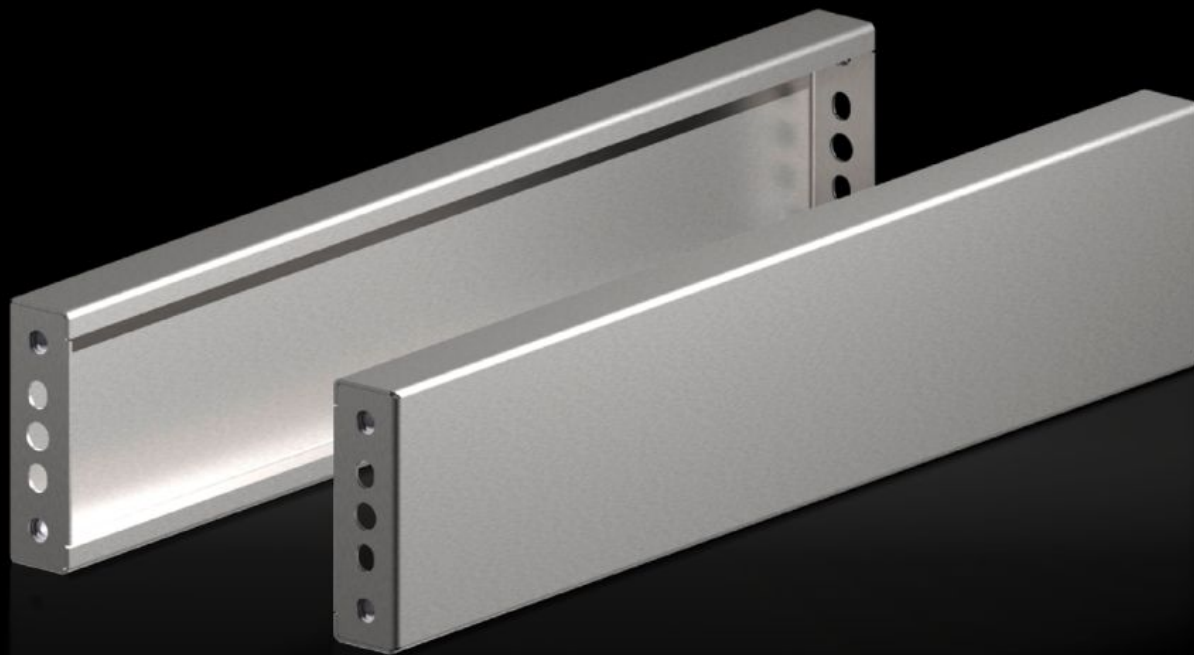

**VX 8660.072**

**Obrobe podnožja/podstavka,  
stranice, za VX sistem podnožja/  
podstavka, nerjavno jeklo**

State: 23.5.2026 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# VX 8660.072 - Obrobe podnožja/podstavka, stranice, za VX sistem podnožja/podstavka, nerjavno jeklo Nova različica

Za zaključek stranic podnožja/podstavka se uporabljajo obrobe iz nerjavnega jekla.



## Features

Št. Modela	VX 8660.072
Material	Nerjavno jeklo 1.4301 (AISI 304)
Površinska obdelava	Brušeno, zrnatost 400
Obseg dobave	Sestavni deli
Opomba	Komponent iz sistema podnožja/podstavka 1. generacije ni mogoče kombinirati s komponentami iz sistema podnožja/podstavka 2. generacije
Mere	Višina: 100 mm
Primerno za	Vrsta ohišja: VX VX SE TS PC Globina: = 600 mm
Tipska ocena po UL 50E	Type 1 Type 3R Type 4 Type 4X Type 12
Paketi	2 pc(s).

# Features

---

Neto teža	1,86 kg
Bruto teža	2,118 kg
Carinska tarifna številka	94039910
ETIM 9	EC000721
ETIM 8	EC000721
ECLASS 8.0	27182003
Opis izdelka	VX base/plinth trim panel, sides, H: 100 mm, for D: 600 mm, stainless steel, 1.4301

# Approvals

---

Approvals	UL + C-UL - FTTA
-----------	------------------