


Rittal – The System.

Faster – better – everywhere.

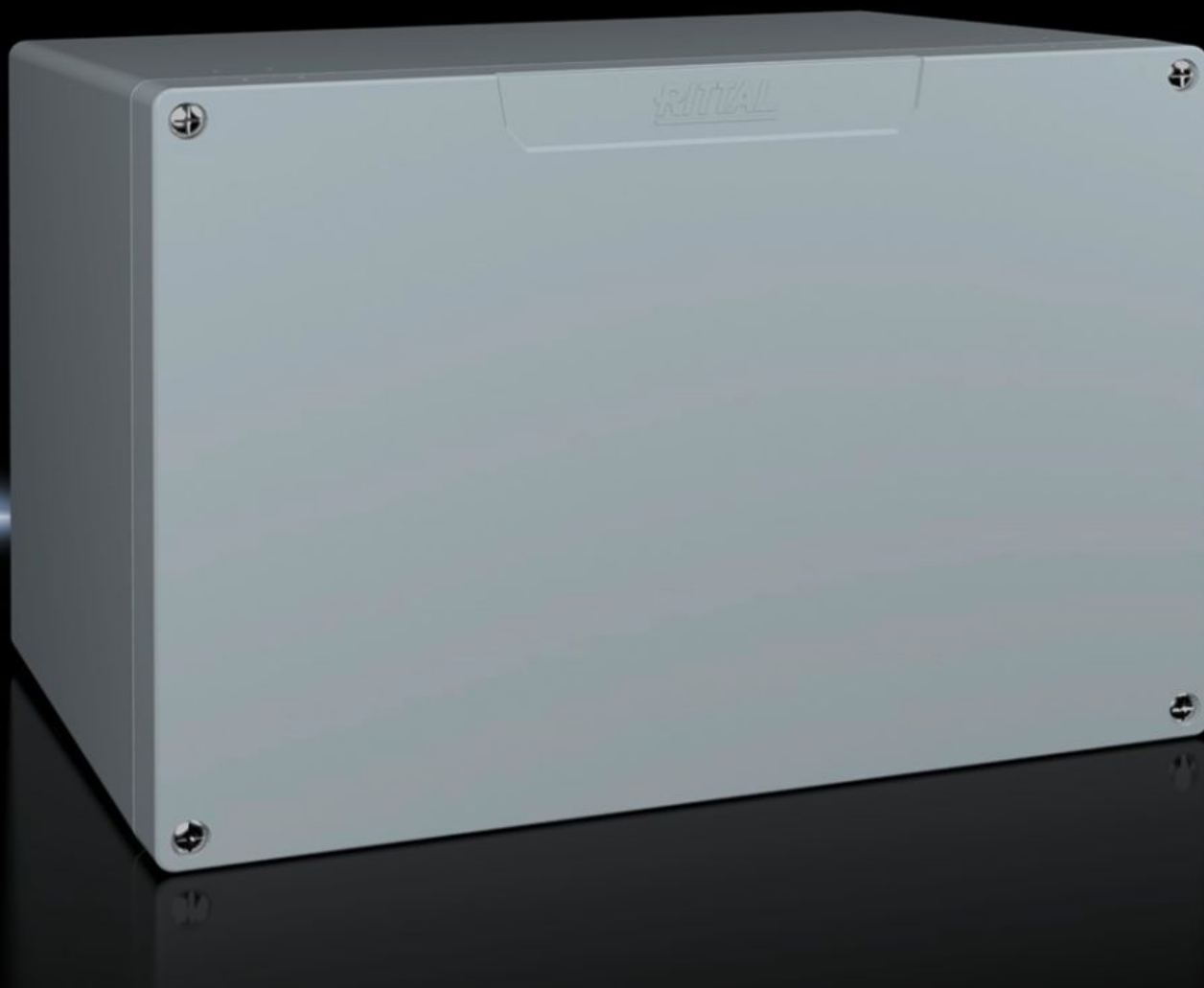

GA 9119.210

Lita aluminijasta ohišja GA

State: 10.5.2026 (Source: rittal.com/si-sl)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



GA 9119.210 - Lita aluminijasta ohišja GA

Lito aluminijasto ohišje z zaključnim premazom. Razred zaščite IP 66.



Features

Št. Modela	GA 9119.210
Material	Ohišje: lito aluminijasto Pokrov: lito aluminijasto, gumeno CR tesnilo po celotnem obodu
Površinska obdelava	Teksturirana barva
Barva	RAL 7001
Obseg dobave	Ohišje s pokrovom Vijaki pokrova, pritrjeni Vijaki za pritrnitev podpornih tirnic Vijak za priklop ozemljitvenega PE vodnika
Protection category NEMA	NEMA 4
Razred zaščite po IEC 60 529	IP 66
IK koda	IK08
Mere	Širina: 330 mm Višina: 230 mm Globina: 183 mm
Osnovni material	Cast aluminium
Paketi	1 pc(s).
Neto teža	4,5 kg
Bruto teža	4,821 kg
Carinska tarifna številka	84879090

Features

ETIM 9	EC000261
ECLASS 8.0	27180101
Opis izdelka	GA Cast aluminium enclosure, WHD: 330x230x181 mm, Cast aluminum, without mounting plate, with cover

Approvals

Explanations	Declaration of conformity Declaration of conformity UK
--------------	---